


# Novastar Side Panel for Slim-Line

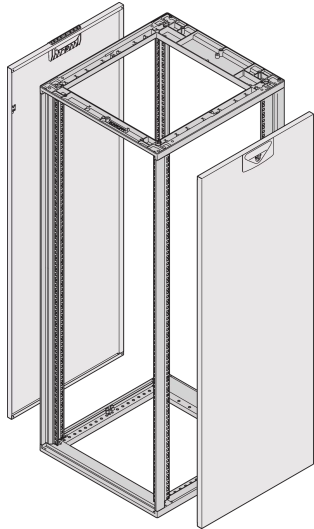

Steel Side Panels for Slim.Line aluminum frame with quick fastener for easy mounting and installation. Schroff delivers cladding parts with grounding cable installed and tested

## CERTIFICATIONS



## FEATURES

Side panel with quarter-turn fastener, includes grounding

St, 1 mm

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Panel

**Material:** Steel

Table 1/2

| Catalog Number | Rack Height | Height | Depth | Package Quantity | Color      | Color Code |
|----------------|-------------|--------|-------|------------------|------------|------------|
| 26230-173      | 16U         | 709mm  | 800mm | 2                | Light Grey | RAL 7035   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 26230-136     | 43U         | 1909mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-137     | 47U         | 2087mm | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-138     | 47U         | 2087mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-172     | 12U         | 589mm  | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-174     | 20U         | 945mm  | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-175     | 25U         | 1167mm | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-176     | 34U         | 1567mm | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-177     | 38U         | 1745mm | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-178     | 43U         | 1967mm | 800mm  | 2                | Light Grey | RAL 7035   |
| 26230-179     | 47U         | 2145mm | 800mm  | 2                | Light Grey | RAL 7035   |
| 25230-160     | 29U         | 1345mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-161     | 29U         | 1345mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-162     | 29U         | 1345mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-163     | 29U         | 1345mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-164     | 29U         | 1345mm | 1000mm | 2                | Black Grey | RAL 7021   |
| 26230-160     | 29U         | 1345mm | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-161     | 29U         | 1345mm | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-162     | 29U         | 1345mm | 800mm  | 2                | Light Grey | RAL 7035   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 26230-163     | 29U         | 1345mm | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-164     | 29U         | 1345mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 25230-070     | 6U          | 357mm  | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-071     | 9U          | 490mm  | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-072     | 12U         | 589mm  | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-073     | 16U         | 709mm  | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-074     | 20U         | 945mm  | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-075     | 25U         | 1167mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-076     | 34U         | 1567mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-077     | 38U         | 1745mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-078     | 43U         | 1967mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-079     | 47U         | 2145mm | 500mm  | 2                | Black Grey | RAL 7021   |
| 25230-113     | 12U         | 531mm  | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-114     | 12U         | 531mm  | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-115     | 16U         | 709mm  | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-116     | 16U         | 709mm  | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-117     | 20U         | 887mm  | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-118     | 20U         | 887mm  | 1000mm | 2                | Black Grey | RAL 7021   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 25230-119     | 25U         | 1109mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-120     | 6U          | 357mm  | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-121     | 9U          | 490mm  | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-122     | 12U         | 589mm  | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-123     | 16U         | 709mm  | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-124     | 20U         | 945mm  | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-125     | 25U         | 1167mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-126     | 34U         | 1567mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-127     | 38U         | 1745mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-128     | 43U         | 1967mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-129     | 47U         | 2145mm | 600mm  | 2                | Black Grey | RAL 7021   |
| 25230-130     | 25U         | 1109mm | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-131     | 34U         | 1509mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-132     | 34U         | 1509mm | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-133     | 38U         | 1687mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-134     | 38U         | 1687mm | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-135     | 43U         | 1909mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-136     | 43U         | 1909mm | 1000mm | 2                | Black Grey | RAL 7021   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 25230-137     | 47U         | 2087mm | 900mm  | 2                | Black Grey | RAL 7021   |
| 25230-138     | 47U         | 2087mm | 1000mm | 2                | Black Grey | RAL 7021   |
| 25230-172     | 12U         | 589mm  | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-173     | 16U         | 709mm  | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-174     | 20U         | 945mm  | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-175     | 25U         | 1167mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-176     | 34U         | 1567mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-177     | 38U         | 1745mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-178     | 43U         | 1967mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 25230-179     | 47U         | 2145mm | 800mm  | 2                | Black Grey | RAL 7021   |
| 26230-070     | 6U          | 357mm  | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-071     | 9U          | 490mm  | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-072     | 12U         | 589mm  | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-073     | 16U         | 709mm  | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-074     | 20U         | 945mm  | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-075     | 25U         | 1167mm | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-076     | 34U         | 1567mm | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-077     | 38U         | 1745mm | 500mm  | 2                | Light Grey | RAL 7035   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 26230-078     | 43U         | 1967mm | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-079     | 47U         | 2145mm | 500mm  | 2                | Light Grey | RAL 7035   |
| 26230-113     | 12U         | 531mm  | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-114     | 12U         | 531mm  | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-115     | 16U         | 709mm  | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-116     | 16U         | 709mm  | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-117     | 20U         | 887mm  | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-118     | 20U         | 887mm  | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-119     | 25U         | 1109mm | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-120     | 6U          | 357mm  | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-121     | 9U          | 490mm  | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-122     | 12U         | 589mm  | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-123     | 16U         | 709mm  | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-124     | 20U         | 945mm  | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-125     | 25U         | 1167mm | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-126     | 34U         | 1567mm | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-127     | 38U         | 1745mm | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-128     | 43U         | 1967mm | 600mm  | 2                | Light Grey | RAL 7035   |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Color      | Color Code |
|---------------|-------------|--------|--------|------------------|------------|------------|
| 26230-129     | 47U         | 2145mm | 600mm  | 2                | Light Grey | RAL 7035   |
| 26230-130     | 25U         | 1109mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-131     | 34U         | 1509mm | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-132     | 34U         | 1509mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-133     | 38U         | 1687mm | 900mm  | 2                | Light Grey | RAL 7035   |
| 26230-134     | 38U         | 1687mm | 1000mm | 2                | Light Grey | RAL 7035   |
| 26230-135     | 43U         | 1909mm | 900mm  | 2                | Light Grey | RAL 7035   |

| Table 2/2      |               |            |                |            |
|----------------|---------------|------------|----------------|------------|
| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
| 26230-173      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-136      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-137      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-138      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-172      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-174      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-175      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-176      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-177      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-178      | Powder Coated | Side Panel | RoHS           | No         |

| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
|----------------|---------------|------------|----------------|------------|
| 26230-179      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-160      | Powder Coated | Side Panel |                | No         |
| 25230-161      | Powder Coated | Side Panel |                | No         |
| 25230-162      | Powder Coated | Side Panel |                | No         |
| 25230-163      | Powder Coated | Side Panel |                | No         |
| 25230-164      | Powder Coated | Side Panel |                | No         |
| 26230-160      | Powder Coated | Side Panel |                | No         |
| 26230-161      | Powder Coated | Side Panel |                | No         |
| 26230-162      | Powder Coated | Side Panel |                | No         |
| 26230-163      | Powder Coated | Side Panel |                | No         |
| 26230-164      | Powder Coated | Side Panel |                | No         |
| 25230-070      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-071      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-072      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-073      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-074      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-075      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-076      | Powder Coated | Side Panel | RoHS           | No         |



| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
|----------------|---------------|------------|----------------|------------|
| 25230-077      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-078      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-079      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-113      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-114      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-115      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-116      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-117      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-118      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-119      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-120      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-121      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-122      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-123      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-124      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-125      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-126      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-127      | Powder Coated | Side Panel | RoHS           | No         |

| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
|----------------|---------------|------------|----------------|------------|
| 25230-128      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-129      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-130      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-131      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-132      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-133      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-134      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-135      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-136      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-137      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-138      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-172      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-173      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-174      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-175      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-176      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-177      | Powder Coated | Side Panel | RoHS           | No         |
| 25230-178      | Powder Coated | Side Panel | RoHS           | No         |

| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
|----------------|---------------|------------|----------------|------------|
| 25230-179      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-070      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-071      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-072      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-073      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-074      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-075      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-076      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-077      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-078      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-079      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-113      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-114      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-115      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-116      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-117      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-118      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-119      | Powder Coated | Side Panel | RoHS           | No         |

| Catalog Number | Finish        | Type       | Certifications | Quick Ship |
|----------------|---------------|------------|----------------|------------|
| 26230-120      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-121      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-122      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-123      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-124      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-125      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-126      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-127      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-128      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-129      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-130      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-131      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-132      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-133      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-134      | Powder Coated | Side Panel | RoHS           | No         |
| 26230-135      | Powder Coated | Side Panel | RoHS           | No         |

## ADDITIONAL PRODUCT DETAILS

---

Optionally the quarter-turn fastener can be fitted with a side panel lock.

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**