


# Varistar Side Separating Wall

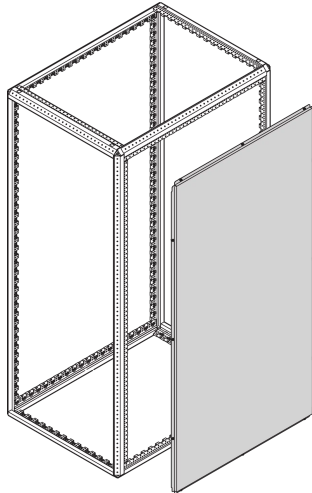

Side panel for side by side cabinets replacing 2 individual cabinet side panles. The seperating panel is mounted between to racks and fully compatible with all air blanking panels.

## CERTIFICATIONS



## FEATURES

Prevents unauthorized access

For cabinets arranged in rows, wall replaces individual cabinet side walls

## SPECIFICATIONS

|                      |                      |
|----------------------|----------------------|
| <b>Finish:</b>       | Aluminum-Zinc Plated |
| <b>Product Type:</b> | Cabinet/Rack Panel   |
| <b>Material:</b>     | Steel                |

Table 1/1

| Catalog Number | Rack Height | Height | Depth  | Package Quantity | Type            | Quick Ship |
|----------------|-------------|--------|--------|------------------|-----------------|------------|
| 23130-580      | 52U         | 2450mm | 1000mm | 1                | Separating Wall | No         |

| CatalogNumber | Rack Height | Height | Depth  | Package Quantity | Type            | Quick Ship |
|---------------|-------------|--------|--------|------------------|-----------------|------------|
| 23130-485     | 47U         | 2200mm | 1200mm | 1                | Separating Wall | No         |
| 23130-480     | 42U         | 2000mm | 1000mm | 1                | Separating Wall | No         |
| 23130-508     | 42U         | 2000mm | 1100mm | 1                | Separating Wall | No         |
| 23130-510     | 52U         | 2450mm | 1100mm | 1                | Separating Wall | No         |
| 23130-481     | 42U         | 2000mm | 1200mm | 1                | Separating Wall | No         |
| 23130-581     | 52U         | 2450mm | 1200mm | 1                | Separating Wall | No         |
| 23130-484     | 47U         | 2200mm | 1000mm | 1                | Separating Wall | No         |
| 23130-509     | 47U         | 2200mm | 1100mm | 1                | Separating Wall | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**