



nVent CADDY Cat 425 Adjustable Cable Support with BC Beam Clamp

Data Solutions

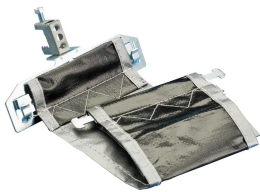

CERTIFICATIONS

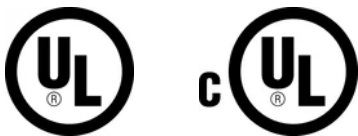

FEATURES

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Simple unlocking and locking of bar allows for additional cables to be added easily after installation

Adjustable strap allows for multiple support sizes to reduce inventory

Cost effective alternative to expensive cable tray

cULus® Listed and complies with NEC® and TIA requirements for structured cabling systems

Suitable for air handling spaces (plenum)

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Diameter (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT425BC	Steel, Polyethylene	nVent CADDY Armour, Electrogalvanized	100mm, 150mm	518mm ²	425	325

Table 2/2

Catalog Number	Cable Capacity, Cat 6A	Flange Thickness (FT)	Static Load
CAT425BC	210	3.2 – 12.7mm	450N

DIAGRAMS

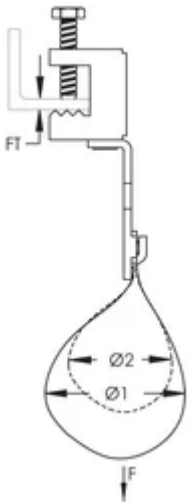

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE