



Industrial Stack Bonding Assembly, Lug to Lug

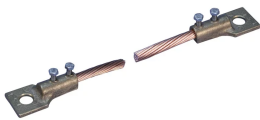

CERTIFICATIONS

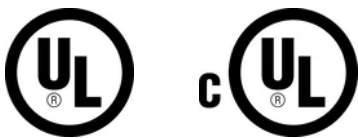

FEATURES

Cast lug assembly for bonding structural features

SPECIFICATIONS

Material: Copper

Table 1/2

Catalog Number	Finish	Conductor Size	Conductor Type	Cable Length	Hole Size (HS)	A
LPC464	Bare		LPC401	0.91m	19.5 mm	54 mm
LPC46440	Bare	4/0 Concentric		0.91m	19.5 mm	54 mm
LPLC464	Lead Covered		LPC401	0.91m	19.5 mm	54 mm

Table 2/2


Catalog Number	B	Unit Weight	Certifications
----------------	---	-------------	----------------

LPC464	104.8 mm	1.18 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPC46440	104.8 mm	1.55 kg	E202878-Combined_CoC, E202878-Combined_CoC
LPLC464	104.8 mm	3.25 kg	

ADDITIONAL PRODUCT DETAILS

Where applicable, lead covering thickness is a minimum of 1/16" (1.59 mm) and is not included in the stated dimensions.

 DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE