

Air Terminal Base, Horizontal Mount, Imperial Thread

Power Utilities



FEATURES

Can be fastened mechanically or bonded using hot pitch, roofing compound or commercial adhesive on built-up roof surfaces or other location where holes cannot be made


Positive single bolt tension for multi-directional cable clamping

SPECIFICATIONS

Table 1/1

Catalog Number	Conductor Size, UL	Height (H)	Width (W)	Unit Weight
LPA30912	Class 1 - Class 2 (4/0 Max)	20.64 mm	101.600 mm	0.141 kg

DIAGRAMS

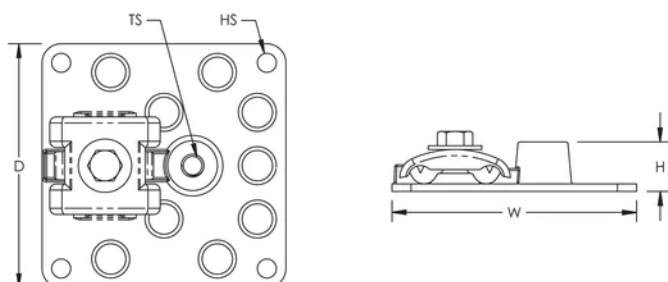

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE