

# Fence Clamp, Two Conductors, 2" Fence Post, 2/0 Solid-250 kcmil Stranded, 50 mm<sup>2</sup> Stranded-120 mm<sup>2</sup> Stranded

## Power Utilities

### CATALOG NUMBER

**FC076DH**



### CERTIFICATIONS



### FEATURES

Theft-deterrent appearance

Stainless steel hardware included

Tin plating minimizes the risk of corrosion


### PRODUCT ATTRIBUTES

Fence Post Size, Nominal: 2"

Fence Post Outside Diameter, Actual (Ø): 60.45 mm

## DIAGRAMS

---

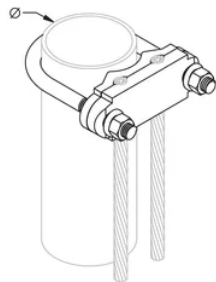

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**