

Bolt Close Conduit/Pipe Clamp



CERTIFICATIONS



FEATURES

Retained bolt and built-in nut means there are less parts to handle or drop

Combo head bolt works with slotted, hex, #3 phillips or #2 robertson drivers

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Article Number	Nut Type	Outer Diameter (OD)	Hole Size (HS)	Static Load 1 (F1)	Static Load 2 (F2)
CD0B	181140	Built-In Nut	17 - 22 mm	7.14 mm	880N	220N
CD1B	181190	Built-In Nut	19 - 25 mm	7.14 mm	880N	220N
CD2.5B	181370	Built-In Nut	31 - 38 mm	7.14 mm	880N	220N


CatalogNumber	Article Number	Nut Type	Outer Diameter (OD)	Hole Size (HS)	Static Load 1 (F1)	Static Load 2 (F2)
CD2B	181150	Built-In Nut	25 - 33 mm	7.14 mm	880N	220N
CD3B	181380	Built-In Nut	36 - 43 mm	7.14 mm	880N	220N
CD4B	181390	Built-In Nut	45 - 48 mm	7.14 mm	880N	220N
CD5B	181470	Built-In Nut	49 - 73 mm	7.14 mm	880N	220N
CD6B	181480	Hex Nut	66 - 76 mm	7.9 mm	1550N	220N
CD7B	181490	Hex Nut	80 - 90 mm	7.9 mm	1550N	220N
CD8B	181500	Hex Nut	95 - 105 mm	7.9 mm	1550N	220N
CD9B	181540	Hex Nut	108 - 115 mm	7.9 mm	1550N	220N

Table 2/2

Catalog Number	Article Number	Certifications
CD0B	181140	UL, cUL
CD1B	181190	cUL, ITB, UL
CD2.5B	181370	cUL, UL
CD2B	181150	cUL, UL
CD3B	181380	UL, cUL, ITB
CD4B	181390	cUL, ITB, UL
CD5B	181470	cUL, UL, ITB
CD6B	181480	
CD7B	181490	

Catalog Number	Article Number	Certifications
CD8B	181500	
CD9B	181540	

DIAGRAMS

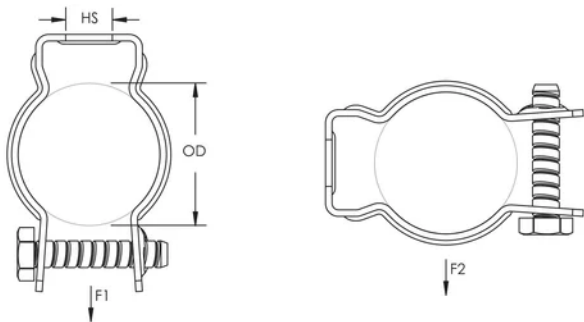

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

