

# Cathodic Bonding Strap, No Holes



## FEATURES

Allows electrical bonding across joints of steel pipe

Approximate electrical equivalent of a 1/0 conductor

Made of soft copper for easy forming

nVent ERICO Cadweld connections to pipe require a CA15 welding material


## SPECIFICATIONS

**Material:** Copper

Table 1/1

Catalog Number	Length (L)	Width (W)	Thickness (T)
CAA817A16	406mm	19.05 mm	1.57 mm
CAA817B600	15420mm	25.4 mm	1.57 mm

## DIAGRAMS

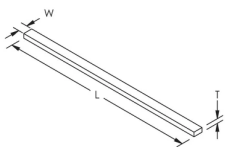

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**