

Drill Distance Gauge, Two Plates



FEATURES

Used for making precise drill hole spacings of ± 1 mm (0.039")

Common applications include axle counters and wheel sensors

SPECIFICATIONS

Material: Steel

Table 1/2


Catalog Number	Article Number	Drill Guide Included	Rail Type	Length 1 (L1)	Length 2 (L2)	Width (W)
DDGTIEFEB145	716534	Yes	S49, S54, UIC60	339.1 mm	145 mm	87.9 mm
DDGSIEMS270	716527	Yes	S49, S54, UIC60	463.8 mm	270 mm	87.9 mm
DDG635119	715263	No	B95	319 mm		87.9 mm

Table 2/2

Catalog Number	Article Number	Height 1 (H1)	Height 2 (H2)	Hole Size (HS)	A
DDGTIEFEB145	716534	50mm	30mm	13.5 mm	145 mm
DDGSIEMS270	716527	50mm	30mm	13.5 mm	270 mm

Catalog Number	Article Number	Height 1 (H1)	Height 2 (H2)	Hole Size (HS)	A
DDG635119	715263	50mm			119 mm

DIAGRAMS

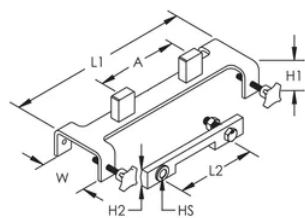

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE