


# Joint Bond T9 Mold Welder Frame Assembly, Power

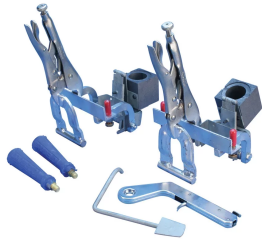

## FEATURES

Replacement welder frame assembly for T9 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

## SPECIFICATIONS

**Rail Type:** 85 lb to 141 lb T-Rail Sections

**Bond Terminal Style:** C

**Material:** Graphite;Steel;Thermoplastic

Table 1/1

| Catalog Number | Conductor Size    | Conductor Outer Diameter, Nominal | Welder Style | Orientation         |
|----------------|-------------------|-----------------------------------|--------------|---------------------|
| PBCT92JLHX     | 2/0 Ropelay       | 12.19mm                           | T9           | Left Hand Assembly  |
| PBCT92JRHX     | 2/0 Ropelay       | 12.19mm                           | T9           | Right Hand Assembly |
| PBCT92SLHX     | 4/0 Ropelay       | 15.49mm                           | T9           | Left Hand Assembly  |
| PBCT92SRHX     | 4/0 Ropelay       | 15.49mm                           | T9           | Right Hand Assembly |
| PBCT92WLHX     | 250 kcmil Ropelay | 19.05mm                           | T9           | Left Hand Assembly  |

| Catalog Number | Conductor Size    | Conductor Outer Diameter, Nominal | Welder Style | Orientation                  |
|----------------|-------------------|-----------------------------------|--------------|------------------------------|
| PBCT92WRHX     | 250 kcmil Ropelay | 19.05mm                           | T9           | Right Hand Assembly          |
| PBCT92WX       | 250 kcmil Ropelay | 19.05mm                           | T9           | Left and Right Hand Assembly |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE