

Rail Base Temporary Signal Bond, T-Handle



FEATURES

Lightweight and durable

Can be used on most common rail types

Hardened contact points on clamps bite through rust and scale

Unique design assures positive contact and firm grip

Cable welded to terminal for electrical reliability

T-shaped handle allows quick and easy tightening by hand

SPECIFICATIONS


Material: Cadmium Bronze;Polyvinylchloride

Table 1/1

| Catalog Number | Color | Length (L) | Width (W) | Height (H) | Rail Foot Thickness (RFT) | Conductor Size |
|-------------------|--------|------------|-----------|------------|---------------------------|---------------------|
| SBS3086S120 WT | Orange | 3048mm | 25.4 mm | 47.6 mm | 15.24 mm Max | 3/16" Bondstrand |
| SBS3086S60W T | Orange | 1524mm | 25.4 mm | 47.6 mm | 15.24 mm Max | 3/16" Bondstrand |
| SBS3086R60W T | Black | 1524mm | 25.4 mm | 47.6 mm | 15.24 mm Max | 3/16" Bondstrand |

| CatalogNumber | Color | Length (L) | Width (W) | Height (H) | Rail Foot Thickness (RFT) | Conductor Size |
|-------------------|--------|------------|-----------|------------|---------------------------|---------------------|
| SBS3086S240 WT | Orange | 6096mm | 25.4 mm | 47.6 mm | 15.24 mm Max | 3/16" Bondstrand |
| SBS3086S48W T | Orange | 1220mm | 25.4 mm | 47.6 mm | 15.24 mm Max | 3/16" Bondstrand |

DIAGRAMS

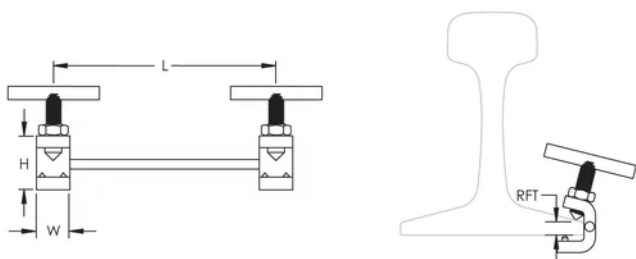

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including cadmium and vinyl chloride, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE