


ATCA Front Panel, Al-Profile, Reinforced With Spring Loading

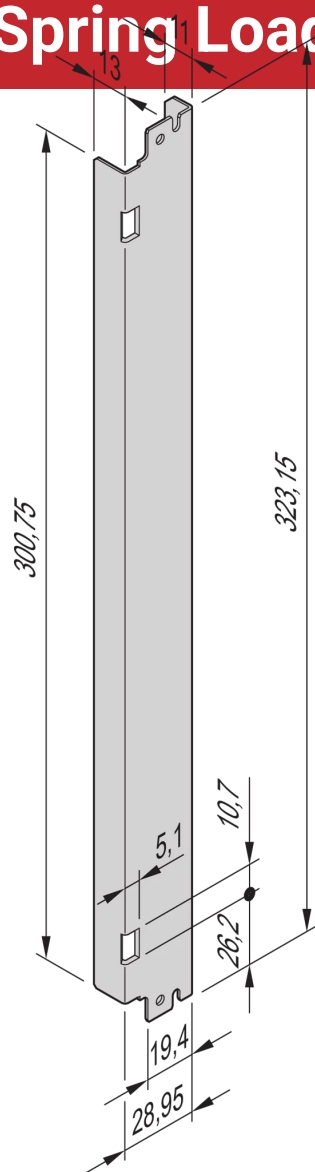

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

CERTIFICATIONS



FEATURES

Configuration: Front panel with IEA handle (with/without spring loading)

Al extrusion; for mesh EMC sealing


SPECIFICATIONS

Depth (D):	1mm
Rack Width:	6HP
Rack Height:	8U
Material:	Aluminum
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2						
Catalog Number	Package Quantity	Handle Type	Front Finish	Rear Finish	Finish	Height (H)
31596-900	1	Lever	Raw	Raw	Passivated	323.15mm
31596-899	1	Plunger	Raw	Raw	Passivated	323.15mm

Table 2/2		
Catalog Number	Width (W)	Quick Ship
31596-900	29mm	No
31596-899	29mm	No

DIAGRAMS

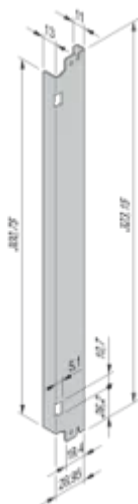

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE