


VME64x System, 4 U, 8 Slot, Open Frame PSU

CATALOG NUMBER

20836-416

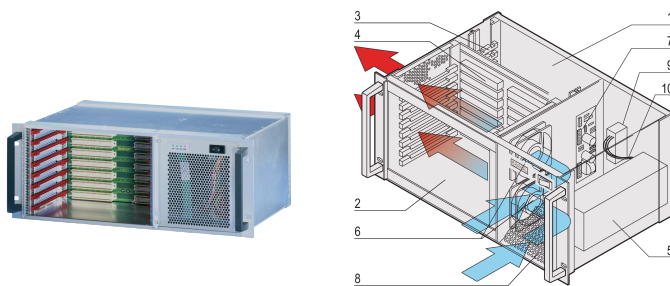

VME64x system for 8 horizontally mounted VME64x boards 6 U, 160 mm. Rear I/ O option. The power for the system is supplied by an open frame power supply.

CERTIFICATIONS



FEATURES

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 560 W (400 W at < 180 VAC)

Backplane VME64x8 slot, 6 U, without P0 plug

Heat dissipation by 2 fans, cooling from front to side; temperature-controlled with fan control module (FCM)

Display module for DC operating voltages, fan and temperature alarm

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W
Input Voltage AC: 100 – 240V
Airflow Direction: Front to Left
Rack Height: 4U
Power Supply Type: Open Frame
Power Supply Included: Yes
Rear I/O: Yes
Complies With: ANSI/VITA 1.1-1997
Depth: 277.5mm
Height: 177mm
Width: 449mm
Power: 350W
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Modified systems available on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE