


# EuropacPRO Divider Plate

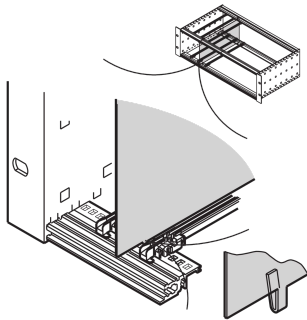

The divider plate enables the user to create a separate area inside a subrack or case. The plate can be clipped into the perforation of the horizontal rails. The subracks or cases have to be disassembled if the plate will be assembled.

## CERTIFICATIONS



## FEATURES

Mounts by clipping into horizontal rails

Space requirement on component side: 2.0 mm

Fitting depends on gasketing method (stainless steel/textile gasket)

## SPECIFICATIONS

|                        |                 |
|------------------------|-----------------|
| <b>Product Family:</b> | EuropacPRO      |
| <b>Product Type:</b>   | Side Panel      |
| <b>Material:</b>       | Stainless Steel |
| <b>Works With:</b>     | Subracks        |

Table 1/1

| Catalog Number | Rack Height | Package Quantity | Depth | Length | Quick Ship |
|----------------|-------------|------------------|-------|--------|------------|
| 34562-761      | 3U          | 1                | 160mm | 160mm  | No         |
| 34562-764      | 6U          | 1                | 220mm | 220mm  | No         |

| Catalog Number | Rack Height | Package Quantity | Depth | Length | Quick Ship |
|----------------|-------------|------------------|-------|--------|------------|
| 34562-763      | 6U          | 1                | 160mm | 160mm  | No         |
| 34562-762      | 3U          | 1                | 220mm | 220mm  | No         |

## ADDITIONAL PRODUCT DETAILS

Subsequent installation of the divider plate in a mounted subrack requires removal of the horizontal rails beforehand.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**