

Standard Universal Sway Brace, 1 1/2" Pipe, 40 DN

CATALOG NUMBER

CSBSTU0150EG



CERTIFICATIONS



FEATURES

Use for both lateral and longitudinal sway brace applications

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Slotted design grabs service pipe for added gripping strength

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

PRODUCT ATTRIBUTES

Article Number: 404387

Material: Steel;Cast Iron

Finish: Electrogalvanized

Pipe Size: 1 1/2"

NB/DN: 40

A: 196.9 mm

B: 25.4 mm

Brace Pipe Size: 1" - 2"

Brace NB/DN: 25 - 50 mm


ADDITIONAL PRODUCT DETAILS

When installed with Schedule 10 and Schedule 40 Service Pipe, use 1" to 2" Schedule 40 NPS as brace member.

When installed with KS D 3507 and KS D 3562 Service Pipe, use 25A to 32A KS D 3562 as brace member.

UL Loads (Listed for Restraints)		
Part Number	Lateral	Longitudinal
	Sch 10/Sch 40 Service Pipe	Sch 10/Sch 40 Service Pipe
CSBSTU0100	2914 N	2914 N
CSBSTU0125	2914 N	2914 N
CSBSTU0150	2914 N	2914 N
CSBSTU0200	2914 N	-

DIAGRAMS

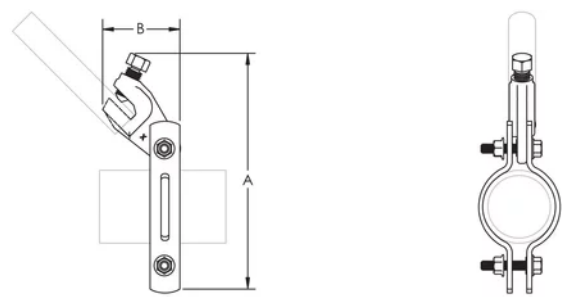

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

