

# Uniklip Equal Tee



## CERTIFICATIONS



## FEATURES

Creates a quick and easy equal tee pathway intersection

Provides optimal support for high-performance low voltage and data cables

Innovative UNIKLIP installation system that installs up to three times faster

IEC 61537 load rating and earthing compliant

No field cutting or modifications required; just drop it in and keep installing the cable tray

Eliminates safety related concerns around field cutting

Tool-free, integrated couplers with Uniklip

## SPECIFICATIONS

**Finish:** Pregalvanized


**Material:** Steel

Table 1/1

| Catalog Number | Article Number | Width (W) | Depth (D) | Length (L) | A      | B     |
|----------------|----------------|-----------|-----------|------------|--------|-------|
| PCT50X050ET    | 850300         | 50 mm     | 49mm      | 375mm      | 202 mm | 91 mm |

| CatalogNumber | Article Number | Width (W) | Depth (D) | Length (L) | A      | B     |
|---------------|----------------|-----------|-----------|------------|--------|-------|
| PCT50X075ET   | 850310         | 75 mm     | 49mm      | 405mm      | 228 mm | 91 mm |
| PCT50X100ET   | 850320         | 100 mm    | 49mm      | 425mm      | 253 mm | 91 mm |
| PCT50X150ET   | 850330         | 150 mm    | 49mm      | 475mm      | 303 mm | 91 mm |
| PCT50X225ET   | 850340         | 225 mm    | 49mm      | 550mm      | 378 mm | 91 mm |
| PCT50X300ET   | 850350         | 300 mm    | 49mm      | 625mm      | 453 mm | 91 mm |
| PCT50X450ET   | 850360         | 450 mm    | 49mm      | 775mm      | 603 mm | 91 mm |
| PCT50X500ET   | 850370         | 500 mm    | 49mm      | 852mm      | 653 mm | 91 mm |
| PCT50X600ET   | 850380         | 600 mm    | 49mm      | 925mm      | 753 mm | 91 mm |

## DIAGRAMS

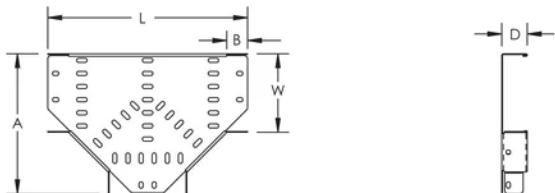

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

