


EuropacPRO Mounting Plate for Use With Cover Plate

Power Utilities

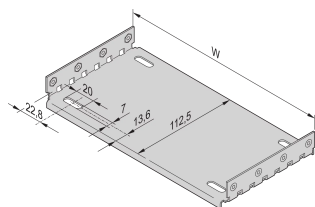

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



FEATURES

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Width	Package Quantity	Depth	Material	Product Family	Product Type
34563-019	63 HP	1	172.5 mm	Aluminum	EuropacPRO	Mounting Plate

CatalogNumber	Rack Width	Package Quantity	Depth	Material	Product Family	Product Type
34563-001	28 HP	1	112.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-003	63 HP	1	112.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-044	84 HP	1	412.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-042	84 HP	1	352.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-009	28 HP	1	172.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-002	42 HP	1	112.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-028	84 HP	1	292.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-026	84 HP	1	232.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-014	42 HP	1	172.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-024	84 HP	1	172.5 mm	Aluminum	EuropacPRO	Mounting Plate
34563-004	84 HP	1	112.5 mm	Aluminum	EuropacPRO	Mounting Plate

Table 2/2			
Catalog Number	Width	Works With	Certifications
34563-019	324.67 mm	Subracks	RoHS
34563-001	146.88 mm	Subracks	RoHS
34563-003	324.67 mm	Subracks	RoHS
34563-044	431.35 mm	Subracks	
34563-042	431.35 mm	Subracks	
34563-009	146.88 mm	Subracks	RoHS

Catalog Number	Width	Works With	Certifications
34563-002	217.99 mm	Subracks	RoHS
34563-028	431.35 mm	Subracks	
34563-026	431.35 mm	Subracks	
34563-014	217.99 mm	Subracks	RoHS
34563-024	431.35 mm	Subracks	RoHS
34563-004	431.35 mm	Subracks	RoHS

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE