


# NW126 Retainer, 0.063" (1.6 mm) Board, 7.25" (184 mm) Long

## CATALOG NUMBER

**NW126-06-7.25**

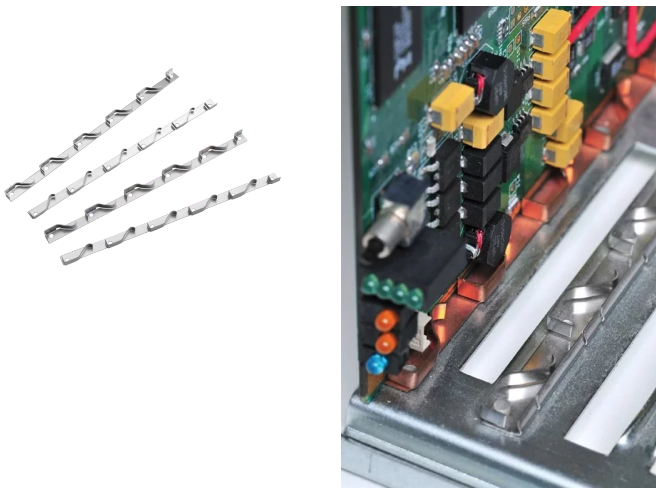

The Series NW126 is an economical PCB retention solution for cold wall applications. Constructed of rugged stainless steel, the independent spring design provides board retention for low shock and vibration applications.

⚠WARNING: This product can expose you to chemicals including beryllium, which is known to the State of California to cause cancer. For more information, go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

## CERTIFICATIONS



## FEATURES

Supports PCB thickness of 1.6 mm (0.063") or 2.4 mm (0.094")

DSCC 85034

Made from stainless steel

Spring based retention design

For cold wall applications

Weight 0.32g/cm (0.029 oz/")

Length 31.75 mm (1.25") to 311.15 mm (12.25"), 24.5 mm (1.0") increments

PRODUCT ATTRIBUTES

|                                  |
|----------------------------------|
| Product Type: PCB Retainer       |
| Type: PCB Tainer (Spring Design) |
| Board Thickness: 1.6mm           |
| Finish: Passivated               |
| Length: 184.2mm                  |

ADDITIONAL PRODUCT DETAILS

From time to time, nVent may modify its product specifications to be in conformity with applicable industry, military or other relevant standards. Unless otherwise mutually agreed in writing, cancelled or superseded military specifications may be certified to the latest or superseding specifications. Products manufactured in conformity with such specifications will be deemed fully compliant whether or not you have been notified of such modifications, even if different from the original specification or those referenced by the customer.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including beryllium, which is known to the State of California to cause cancer. For more information, go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

| North America                                            | Europe                                                   | Asia                                                     | Middle East & India                                      |
|----------------------------------------------------------|----------------------------------------------------------|----------------------------------------------------------|----------------------------------------------------------|
| All locations                                            | Straubenhardt, Germany                                   | Shanghai, China                                          | Dubai, United Arab Emirates                              |
| +1.763.422.2661                                          | +49.7082.794.0                                           | +86.21.2412.6943                                         | +971.4.378.1700                                          |
| Chat with us:                                            | Betschdorf, France                                       | Qingdao, China                                           | Bangalore, India                                         |
| <a href="http://nvent.com/schroff">nvent.com/schroff</a> | +33.3.88.90.64.90                                        | +86.532.8771.6101                                        | +91.80.6715.2001                                         |
|                                                          | Warsaw, Poland                                           | Singapore                                                | Istanbul, Turkey                                         |
|                                                          | +48.22.209.98.35                                         | +65.6768.5800                                            | +90.216.250.7374                                         |
|                                                          | Assago, Italy                                            | Shin-Yokohama, Japan                                     | Chat with us:                                            |
|                                                          | +39.02.932.7141                                          | +81.45.476.0271                                          | <a href="http://nvent.com/schroff">nvent.com/schroff</a> |
|                                                          | Chat with us:                                            | Chat with us:                                            |                                                          |
|                                                          | <a href="http://nvent.com/schroff">nvent.com/schroff</a> | <a href="http://nvent.com/schroff">nvent.com/schroff</a> |                                                          |



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE