


# Guide Rail With Coding, preassembled ESD Clip for CompactPCI/ VME64x, PC

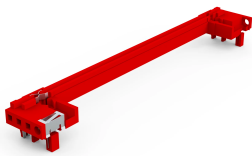

## CERTIFICATIONS



## FEATURES

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

## SPECIFICATIONS

|                        |                                                                                    |
|------------------------|------------------------------------------------------------------------------------|
| <b>Works With:</b>     | Sub racks; Cases; 19" Chassis; Systems                                             |
| <b>Type:</b>           | Coding and Preassembled ESD Clips                                                  |
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac |
| <b>Material:</b>       | Fiber-Reinforced Plastic                                                           |
| <b>Product Type:</b>   | Guide Rail                                                                         |

Table 1/2

| Catalog Number | Color | Package Quantity | Board Depth | Groove Width | Complies With | Rail Type |
|----------------|-------|------------------|-------------|--------------|---------------|-----------|
| 24568-853      | Red   | 10               | 70mm        | 2            | EN 45545-2    | Top       |
| 24568-855      | Red   | 10               | 70mm        | 2            | EN 45545-2    | Bottom    |
| 24568-854      | Grey  | 10               | 70mm        | 2            | EN 45545-2    | Top       |
| 24568-856      | Grey  | 10               | 70mm        | 2            | EN 45545-2    | Bottom    |
| 24568-847      | Red   | 10               | 160mm       | 2            | EN 45545-2    | Bottom    |
| 24568-850      | Red   | 10               | 160mm       | 2            | EN 45545-2    | Top       |
| 24568-848      | Grey  | 10               | 160mm       | 2            | EN 45545-2    | Bottom    |
| 24568-851      | Grey  | 10               | 160mm       | 2            | EN 45545-2    | Top       |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 24568-853      | No         |
| 24568-855      | No         |
| 24568-854      | No         |
| 24568-856      | No         |
| 24568-847      | No         |
| 24568-850      | No         |
| 24568-848      | No         |
| 24568-851      | No         |

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE