


# Sleeves for M2.5

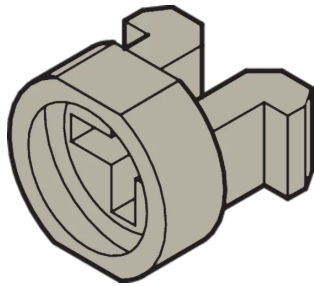

Sleeve guides the collar screw when fastening the front panel.

## CERTIFICATIONS



## FEATURES

Sleeve guides the collar screw when fastening the front panel

Sleeve is inserted into the elongated hole of the front panel

## SPECIFICATIONS

**Works With:** Front Panels

**Product Type:** Sleeve

Table 1/2

Catalog Number	Material	Finish	Color	Package Quantity	Color Code	Depth (D)
21100-886	Brass	Organic Top Coat		100		4.4mm
21100-662	Stainless Steel			100		4.4mm
21100-660	Brass	Nickel Plated		100		4.4mm

CatalogNumber	Material	Finish	Color	Package Quantity	Color Code	Depth (D)
21100-591	Polyamide 6		Jet Black	100	RAL 9005	6.9mm
21100-464	Polyamide 6		Pebble Grey	100	RAL 7032	6.9mm
21100-659	Brass	Nickel Plated		10		
21100-661	Stainless Steel			10		
21100-885	Brass			10		

Table 2/2


Catalog Number	Height (H)	Width (W)	Flammability Rating	Quick Ship
21100-886	6mm	8mm		No
21100-662	6mm	8mm		No
21100-660	6mm	8mm		No
21100-591	6mm	6.8mm	UL® 94V-2	No
21100-464	6mm	6.8mm	UL® 94V-2	No
21100-659				No
21100-661				No
21100-885				No

## ADDITIONAL PRODUCT DETAILS

---

Metal sleeves on the partial front panels must be pressed in.

All sleeves can be used for front panel > 2 HP.

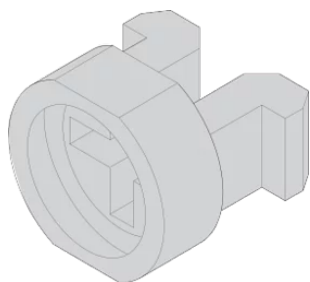

**WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**