


# ProLine Containment System Express Sealed Doors

## Data Solutions

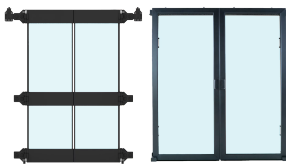

Designed for 48-inch (1200mm) wide aisles. Can also provide benefits for wider aisles. A 48-inch (1219 mm) wide version seals aisles from 46-inch (1168 mm) to 54-inch (1372 mm) and a 72-inch (1829 mm) wide version seals aisles from 70-inch (1778 mm) to 78-inch (1981 mm). Custom solutions can also provide benefits for wider aisles.

### FEATURES

Aisle doors either slide or swing bi-directionally to provide quick access to aisle way

Designed for 48-inch (1200 mm) wide aisles, but can also provide benefits for wider aisles

The Bi-directional doors require a minimum 6-inch (152 mm) clearance from the front edge of the cabinet along its entire height for the hinges to attach

Works with a variety of cabinets 76-inch (1930 mm) and taller

Doors can be installed to hot or cold aisle

Doors attached to side of rack magnetically

Tool-less design allows for easy installation, removal, and re-installation

Solution for both new builds and retrofit data centers

Clear, transparent door and roof panels provide maximum light to aisleway

Express containment system includes magnetic mounting for quick-install

Express containment models features tool-less installation with exclusive Magswitch technology

### SPECIFICATIONS

**Material:** Polycarbonate; ABS

**Finish:** Powder Coated

Table 1/2

Catalog Number	Article Number	Height	Width	Depth	Color	Color Code
UAC2DDR42U	38623	1981mm	870mm	102mm	Light Gray	RAL 7035
UAC2DDR45U	38626	2115mm	870mm	102mm	Jet Black	RAL 9005
UACSD4B	38617	2235mm	1556mm	318mm	Jet Black	RAL 9005
UACSD6B	38627	2235mm	2165mm	318mm	Jet Black	RAL 9005

Table 2/2

Catalog Number	Article Number	Rack Units
UAC2DDR42U	38623	42U
UAC2DDR45U	38626	45U
UACSD4B	38617	42U
UACSD6B	38627	45U

## ADDITIONAL PRODUCT DETAILS

Custom sizes are available

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**