


# Cable Entry Gland Plate Round Frame, CCFRBK

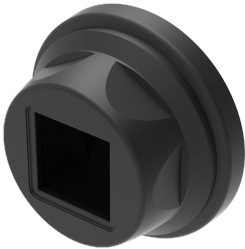

## FEATURES

CCFRBK Round Frame only; CCFRM Locking Adapter and CCFRMNUT Counter Nut sold separately

Halogen and silicone free component

The frames, inlays and grommets can be combined in many ways ensuring you many versatile configuration options

No need to disassemble and reconnect connectors on cables so manufactures warranty is not voided

CCFR cable entry is quick and easy to assemble

It is made of a sturdy, glass-fiber reinforced plastic

CCFG grommets needs to be ordered separately

CCFD dividers are bought separately as needed

Operating Temperature: -40 to 120 °C / -40 to 248 °F

SPECIFICATIONS

| Table 1/1      |                |        |       |       |                         |              |
|----------------|----------------|--------|-------|-------|-------------------------|--------------|
| Catalog Number | Article Number | Height | Width | Depth | Material                | Finish       |
| CCFR2032       | 59667          | 48mm   | 48mm  | 22mm  | Thermoplastic Elastomer | Smooth Matte |
| CCFR4063       | 59668          | 80mm   | 80mm  | 22mm  | Thermoplastic Elastomer | Smooth Matte |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE