

# ProLine Gold Series 2-Bay Desk Console Type 12, 1175x1250x469, Lt Gray, Steel

## CATALOG NUMBER

**PGLD12135DC**



The ProLine Gold Series Double-Bay Desk Console provides an ideal surface for mounting HMI controls such as keyboards, switches, lights or dials, and it is ergonomically designed so operators can sit or stand while working. With front and rear doors for easy access, the console provides a large space for mounting internal components and controls and can be configured in an arc by using the wedge accessory.

## INDUSTRY STANDARDS

UL 508A Listed; Type 12; File Number E61997

cUL Listed per CSA C22.2 No 94; File No. E61997

NEMA/EEMAC Type 12

IEC 60529, IP 55

## FEATURES

25-degree sloped top

Seams continuously welded and ground smooth

Top door prop allows for single-handed operation

Built-in top door handle

Quarter-turn latches hold top door securely closed

ProLine latching system and key locking swing handles on front doors and on rear doors of dual-access enclosures

Internal rails on dual-access enclosures facilitate mounting of ProLine internal components

Full access provides maximum mounting space and easy access to interior components

## PRODUCT ATTRIBUTES

Article Number: 14385

Height (H): 1175mm

Width (W): 1250mm

Depth (D): 469mm

Material: Mild Steel


Finish: Powder Coated

Color: Light Gray

Color Code: RAL 7035

Thickness (T): 1.9mm

## DIAGRAMS

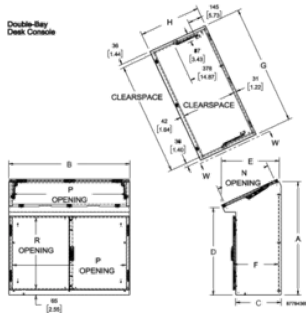

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**