


ProLine Sloped-Front HMI Enclosure Upper Front Door

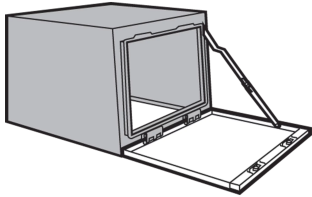

Solid doors are available with or without windows. Doors are hinged at lower edge and have quarter-turn latches. A stop arm assembly holds the door at 95 degrees (horizontal) from its closed position. Standard latch and insert options are available. Ground stud and mounting hardware are included. Seamless polyurethane foam-in-place gasket assures watertight and dust-tight seal. Window doors feature a maximum size .25-in.-thick polycarbonate window with a smoke-gray tint. Window is field-replaceable.

FEATURES

Doors are hinged at lower edge and have quarter-turn latches

Ground stud and mounting hardware

SPECIFICATIONS

Color: Light Gray
Material: Mild Steel
Finish: Powder Coated
Color Code: RAL 7035

Table 1/1						
Catalog Number	Article Number	Height	Width	Depth	Thickness	Window Size
PDS46F	36639	400mm	600mm	565mm	1.52mm	
PDS512F	36669	500mm	1200mm	565mm	1.52mm	
PDS56F	36649	500mm	600mm	565mm	1.52mm	
PDS58F	36659	500mm	800mm	565mm	1.52mm	
PDS712F	36699	700mm	1200mm	565mm	1.52mm	
PDS76F	36679	700mm	600mm	565mm	1.52mm	
PDS78F	36689	700mm	800mm	565mm	1.52mm	
PDW46F	36709	400mm	600mm	565mm	1.52mm	254 x 432mm
PDW56F	36719	500mm	600mm	565mm	1.52mm	362 x 432mm
PDW56W16	36729	500mm	600mm	565mm	1.52mm	254 x 318mm
PDW58F	36739	500mm	800mm	565mm	1.52mm	362 x 635mm
PDW76F	36749	700mm	600mm	565mm	1.52mm	559 x 432mm
PDW76W21	36759	700mm	600mm	565mm	1.52mm	330 x 432mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE