


# nVent LENTON Speed Sleeve Transition Adaptor

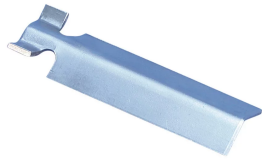

nVent LENTON Speed Sleeve Transition Adaptors allow the nVent LENTON Speed Sleeve to be used as a transition splice. The transition adaptors are simply placed inside the sleeve underneath the straps of the smaller bar end.

## FEATURES

Bars can be individually secured

Fast, one-man installation

Requires only a lightweight ratchet wrench to install

Can be used to splice two smaller bars

## SPECIFICATIONS

**Finish:** Plain

**Material:** Steel

Table 1/1

| Catalog Number | Article Number | Length (L) | Width (W) | Unit Weight |
|----------------|----------------|------------|-----------|-------------|
| RBW3997        |                | 86mm       | 27 mm     | 0.03 kg     |
| RBW3999        | 145565         | 86mm       | 38 mm     | 0.04 kg     |
| RBW3998        |                | 86mm       | 29 mm     | 0.04 kg     |
| RBW39910       |                | 111mm      | 38 mm     | 0.05 kg     |

 
| Catalog Number | Article Number | Length (L) | Width (W) | Unit Weight |
|----------------|----------------|------------|-----------|-------------|
| RBW39911       |                | 146mm      | 51 mm     | 0.11 kg     |
| RBW39914       |                | 152mm      | 57 mm     | 0.32 kg     |

## ADDITIONAL PRODUCT DETAILS

nVent LENTON Speed Sleeve is a compression-only splicing system. It should never be used for tension applications.

| LENTON SPEED SLEEVE Transition Adaptors |                |                    |          |          |                   |
|-----------------------------------------|----------------|--------------------|----------|----------|-------------------|
| Rebar Size, Metric                      | Rebar Size, US | Rebar Size, Canada | Sleeve   | Adaptor  | Adaptors Required |
| 25 to 22 mm                             | #8 to #7       | -                  | RBW2688  | RBW3997  | 1                 |
| 28 to 25 mm                             | #9 to #8       | -                  | RBW2689  | RBW3998  | 1                 |
| 32 to 28 mm                             | #10 to #9      | -                  | RBW26810 | RBW3999  | 1                 |
| 36 to 32 mm                             | #11 to #10     | 35M to 30M         | RBW26811 | RBW39910 | 1                 |
| 43 to 36 mm                             | #14 to #11     | 45M to 35M         | RBW26814 | RBW39911 | 2                 |
| 57 to 43 mm                             | #18 to #14     | 55M to 45M         | RBW26818 | RBW39914 | 2                 |

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**