

# ATCA Front Panel Kit With Spring Loading



AdvancedTCA front panel for spring-loaded IEA handle (plunger or lever style) with die-cast end piece in Al-Profile or stainless material.

## CERTIFICATIONS



## FEATURES

Front panel (reinforced with diecast endpiece)

ATCA IEA handle with spring loading

EMC textile gasket and fixing material

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 6HP         |
| <b>Rack Height:</b>    | 8U          |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/2


| Catalog Number | Material | Finish     | Package Quantity | Front Finish | Rear Finish | Depth (D) |
|----------------|----------|------------|------------------|--------------|-------------|-----------|
| 20818-170      | Aluminum | Passivated | 1                | Raw          | Raw         | 1mm       |
| 20818-169      | Aluminum | Passivated | 1                | Raw          | Raw         | 1mm       |

| CatalogNumber | Material        | Finish | Package Quantity | Front Finish | Rear Finish | Depth (D) |
|---------------|-----------------|--------|------------------|--------------|-------------|-----------|
| 20818-161     | Stainless Steel |        | 1                | Raw          | Raw         | 1mm       |
| 20818-160     | Stainless Steel |        | 1                | Raw          | Raw         | 1mm       |

Table 2/2

| Catalog Number | Height (H) | Width (W) | Quick Ship |
|----------------|------------|-----------|------------|
| 20818-170      | 323.15mm   | 28.95mm   | No         |
| 20818-169      | 323.15mm   | 28.95mm   | No         |
| 20818-161      | 323.15mm   | 28.95mm   | No         |
| 20818-160      | 323.15mm   | 28.95mm   | No         |

## DIAGRAMS

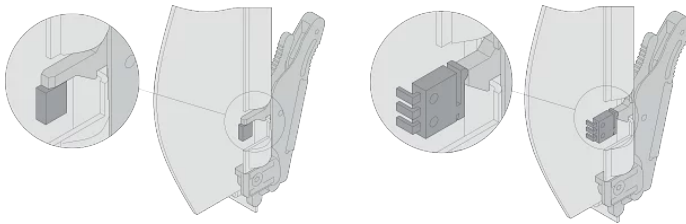

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**