

Front Panel, Front Anodized, Rear Conductive, Unshielded

Front panel, unshielded, front anodized and rear conductive.



CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm

Al, front anodized, conductive

SPECIFICATIONS

Depth (D):	2.5mm
Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle

Table 1/2

Catalog Number	Rack Height	Package Quantity	Mounting	Front Finish	Rear Finish	Treated Edges
30838-043	3U	1	Screw-on Front	Anodized	Conductive	No

CatalogNumber	Rack Height	Package Quantity	Mounting	Front Finish	Rear Finish	Treated Edges
30847-458	2U	1	Screw-on Front	Anodized	Conductive	No
30847-459	2U	1	Screw-on Front	Anodized	Conductive	No
30847-462	4U	1	Screw-on Front	Anodized	Conductive	No
30847-460	2U	1	Screw-on Front	Anodized	Conductive	No
30847-466	5U	1	Screw-on Front	Anodized	Conductive	No
30847-467	5U	1	Screw-on Front	Anodized	Conductive	No
30847-468	5U	1	Screw-on Front	Anodized	Conductive	No
30847-469	5U	1	Screw-on Front	Anodized	Conductive	No


Table 2/2						
Catalog Number	Complies With	EMC Shielding	Height (H)	Width (W)	Certifications	Quick Ship
30838-043	IEC 60297-3-101, IEEE 1101.1/10	No	128.4mm	20mm	RoHS	No
30847-458	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	141.9mm		No
30847-459	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	213mm		No
30847-462	IEC 60297-3-101, IEEE 1101.1/10	No	172.9mm	141.9mm		No
30847-460	IEC 60297-3-101, IEEE 1101.1/10	No	84mm	319.7mm		No
30847-466	IEC 60297-3-101, IEEE 1101.1/10	No	217.4mm	141.9mm		No
30847-467	IEC 60297-3-101, IEEE 1101.1/10	No	217.4mm	213mm		No

CatalogNumber	Complies With	EMC Shielding	Height (H)	Width (W)	Certifications	Quick Ship
30847-468	IEC 60297-3-101, IEEE 1101.1/10	No	217.4mm	319.7mm		No
30847-469	IEC 60297-3-101, IEEE 1101.1/10	No	217.4mm	426.4mm		No

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

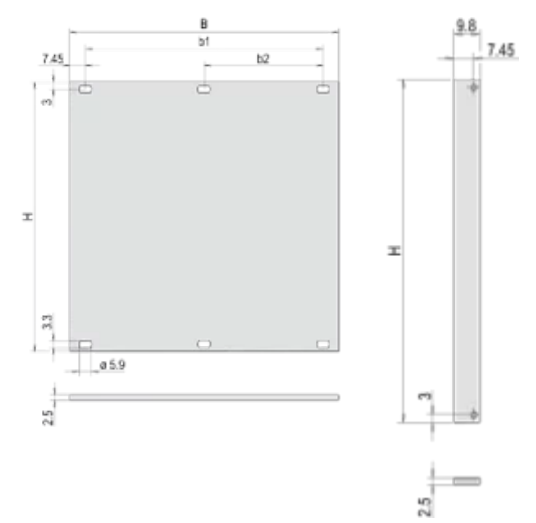

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE