


# Novastar 19" Panel/Slide Mount

## Power Utilities

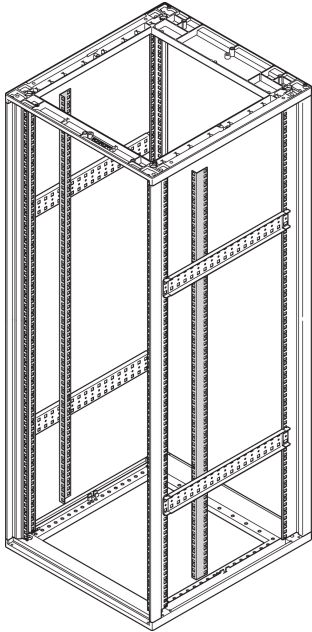

Novastar 19" Panel/Slide Mount Kit with load capacity of 400 kg, ensures easy fitting of 19" components to depth members.

## CERTIFICATIONS



## FEATURES

For recessed installation of 19" components

For fitting to depth members (25 mm grid)

Load carrying capacity 400 kg

## SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Height	Product Type
----------------	-------------	------------------	-------	------------	--------	--------------

27230-172	6 U	1	Black Grey	RAL 7021	267.1 mm	Slide Mount
27230-173	9 U	1	Black Grey	RAL 7021	400.45 mm	Slide Mount
27230-174	12 U	1	Black Grey	RAL 7021	533.8 mm	Slide Mount
27230-175	16 U	1	Black Grey	RAL 7021	711.6 mm	Slide Mount
27230-176	20 U	1	Black Grey	RAL 7021	889.4 mm	Slide Mount
27230-177	25 U	1	Black Grey	RAL 7021	1111.65 mm	Slide Mount
27230-178	34 U	1	Black Grey	RAL 7021	1511.7 mm	Slide Mount
27230-179	38 U	1	Black Grey	RAL 7021	1689.5 mm	Slide Mount
27230-180	43 U	1	Black Grey	RAL 7021	1911.75 mm	Slide Mount
27230-181	47 U	1	Black Grey	RAL 7021	2089.55 mm	Slide Mount

Table 2/2	
Catalog Number	Package Unit
27230-172	Pair
27230-173	Pair
27230-174	Pair
27230-175	Pair
27230-176	Pair
27230-177	Pair
27230-178	Pair
27230-179	Pair

Catalog Number	Package Unit
27230-180	Pair
27230-181	Pair

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE