


# Novastar Perforated Steel Door

## Power Utilities

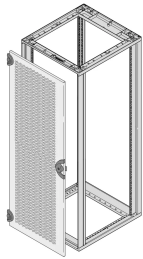

Perforated doors allow 60 % ventilation thus allowing better passive cooling. Novastar perforated doors come with 180° opening angle and aesthetic looks.

## CERTIFICATIONS



## FEATURES

Can be mounted at front and rear

Perforated (60 % ventilation opening)

Opening angle 180°

Lock with key (2233X)

## SPECIFICATIONS

Table 1/2

| Catalog Number | Rack Height | Height   | Width  | Color      | Color Code | Product Type |
|----------------|-------------|----------|--------|------------|------------|--------------|
| 25230-081      | 6 U         | 288.4 mm | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-081      | 6 U         | 288.4 mm | 553 mm | Light Grey | RAL 7035   | Cabinet Door |

| CatalogNumber | Rack Height | Height     | Width  | Color      | Color Code | Product Type |
|---------------|-------------|------------|--------|------------|------------|--------------|
| 25230-082     | 9 U         | 421.75 mm  | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-082     | 9 U         | 421.75 mm  | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-083     | 12 U        | 555.1 mm   | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-083     | 12 U        | 555.1 mm   | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-084     | 16 U        | 732.9 mm   | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-084     | 16 U        | 732.9 mm   | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-085     | 20 U        | 910.7 mm   | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-085     | 20 U        | 910.7 mm   | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-086     | 25 U        | 1132.95 mm | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-086     | 25 U        | 1132.95 mm | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-091     | 29 U        | 1310.75 mm | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-091     | 29 U        | 1310.75 mm | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-087     | 34 U        | 1533 mm    | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-087     | 34 U        | 1533 mm    | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-088     | 38 U        | 1710.8 mm  | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-088     | 38 U        | 1710.8 mm  | 553 mm | Light Grey | RAL 7035   | Cabinet Door |
| 25230-089     | 43 U        | 1933.05 mm | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-089     | 43 U        | 1933.05 mm | 553 mm | Light Grey | RAL 7035   | Cabinet Door |

| CatalogNumber | Rack Height | Height     | Width  | Color      | Color Code | Product Type |
|---------------|-------------|------------|--------|------------|------------|--------------|
| 25230-090     | 47 U        | 2110.85 mm | 553 mm | Black Grey | RAL 7021   | Cabinet Door |
| 26230-090     | 47 U        | 2110.85 mm | 553 mm | Light Grey | RAL 7035   | Cabinet Door |

Table 2/2

| Catalog Number | Type                   |
|----------------|------------------------|
| 25230-081      | Steel Door, Perforated |
| 26230-081      | Steel Door, Perforated |
| 25230-082      | Steel Door, Perforated |
| 26230-082      | Steel Door, Perforated |
| 25230-083      | Steel Door, Perforated |
| 26230-083      | Steel Door, Perforated |
| 25230-084      | Steel Door, Perforated |
| 26230-084      | Steel Door, Perforated |
| 25230-085      | Steel Door, Perforated |
| 26230-085      | Steel Door, Perforated |
| 25230-086      | Steel Door, Perforated |
| 26230-086      | Steel Door, Perforated |
| 25230-091      | Steel Door, Perforated |
| 26230-091      | Steel Door, Perforated |
| 25230-087      | Steel Door, Perforated |

| Catalog Number | Type                   |
|----------------|------------------------|
| 26230-087      | Steel Door, Perforated |
| 25230-088      | Steel Door, Perforated |
| 26230-088      | Steel Door, Perforated |
| 25230-089      | Steel Door, Perforated |
| 26230-089      | Steel Door, Perforated |
| 25230-090      | Steel Door, Perforated |
| 26230-090      | Steel Door, Perforated |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE