


AMC Front Panel With Pull Handle

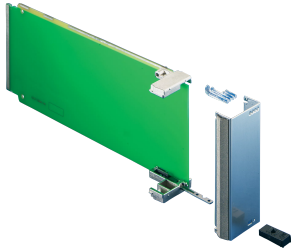

AdvancedMC Front Panel including EMC gasket for AMC.0 Rev. 2.0 Modules.

CERTIFICATIONS



FEATURES

In accordance with AMC.0 R2.0 specification

Front panel for pull-handle mechanism (with cut-outs for light pipe)

For the use together with the AMC Pull-handle mechanism, AMC.0 R2.0

SPECIFICATIONS

Accessory Type: Front panel

Product Type: Front Panel

Table 1/2


Catalog Number	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-682	73.8mm	6HP	Full-Size	Aluminum	Passivated	1
30849-670	148.8mm	4HP		Aluminum	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Aluminum	Passivated	1

CatalogNumber	Height (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-403	73.8mm	4HP	Mid-Size	Stainless Steel		1
30849-404	73.8mm	6HP	Full-Size	Stainless Steel		1
30849-406	148.8mm	4HP	Mid-Size	Stainless Steel		1
30849-407	148.8mm	6HP	Full-Size	Stainless Steel		1
30849-402	73.8mm	3HP	Compact	Stainless Steel		1
30849-658	73.8mm	4HP	Mid-Size	Aluminum	Passivated	1

Table 2/2

Catalog Number	Front Finish	Rear Finish	Depth (D)	Width (W)	Quick Ship
30849-682	Raw	Raw	2.5mm	29mm	No
30849-670	Raw	Raw	2.5mm	19mm	No
30849-694	Raw	Raw	2.5mm	29mm	No
30849-403	Raw	Raw	1mm	19mm	No
30849-404	Raw	Raw	1mm	29mm	No
30849-406	Raw	Raw	1mm	19mm	No
30849-407	Raw	Raw	1mm	29mm	No
30849-402	Raw	Raw	1mm	13.9mm	No
30849-658	Raw	Raw	2.5mm	19mm	No

DIAGRAMS

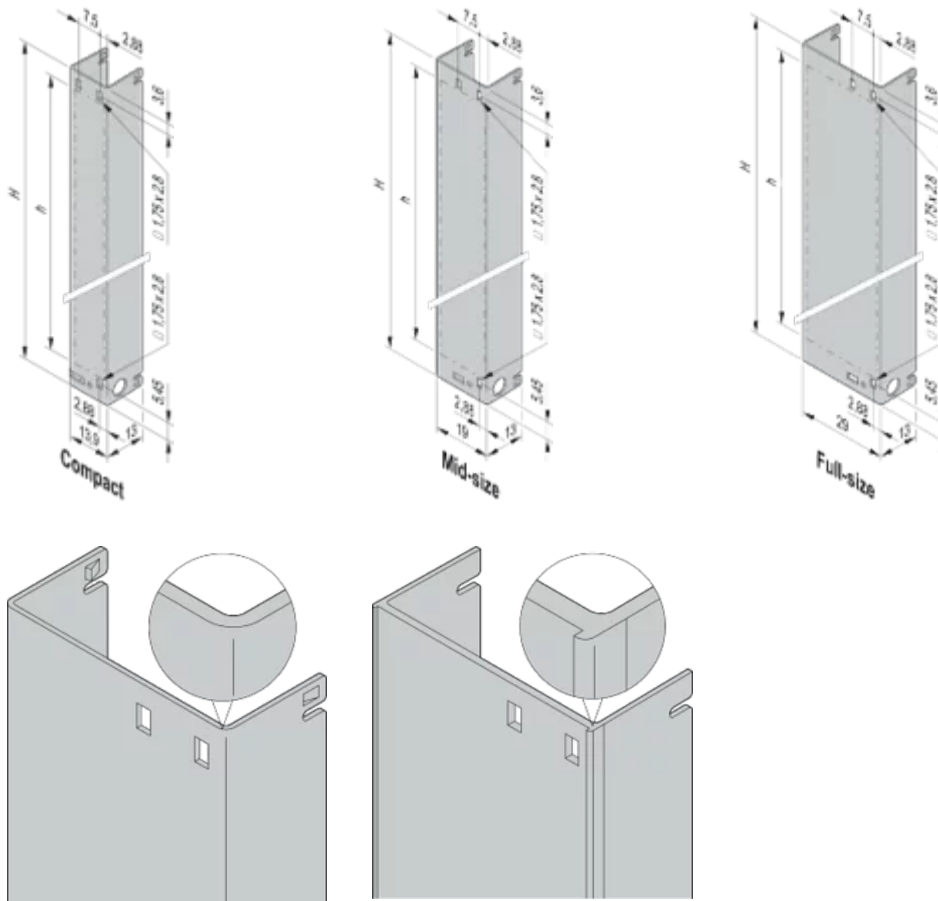

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE