


# EuropacPRO Advanced EMC 45, 19" Subrack Kit for Backplane, Heavy, EMC Shielded, w/wo Front Handle

EMC Shielded subrack for backplane mounting, heavy version with tox welded side panels.

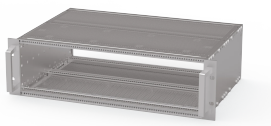

## CERTIFICATIONS



## FEATURES

Advanced EMC subrack with on average 45% improved RF shielding effectiveness compared to a standard EuropacPRO, tested according to EN 61000-5-7\*Pending

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1

Additional side panel covers for increased lateral RF shielding

Horizontal rails and side panels of type H ("Heavy") for harsh environments

Rear horizontal rail for direct backplane mounting without insulation strip

Shock and vibration resistant up to 5 g, tested in accordance with EN 61373 class 1, category B

Installation load up to 15 kg

Compatible with textile and stainless-steel gaskets

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Versions with and without front handles

Supplied as space-saving flat-pack, modifications and assembly services on request

## SPECIFICATIONS

**Static Load:** 15kg  
**Product Type:** Subrack/Chassis  
**EMC Shielding:** Yes

Table 1/3

| Catalog Number | Rack Height | Depth | Package Quantity | For Mounting | Board Depth | EMC Gasket Type |
|----------------|-------------|-------|------------------|--------------|-------------|-----------------|
| 24563-900      | 3U          | 235mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-901      | 3U          | 295mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-903      | 3U          | 355mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-910      | 6U          | 235mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-911      | 6U          | 295mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-913      | 6U          | 355mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-950      | 3U          | 235mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-951      | 3U          | 295mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-953      | 3U          | 355mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-960      | 6U          | 235mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-961      | 6U          | 295mm | 1                | Backplane    | 160mm       | Textile         |
| 24563-963      | 6U          | 355mm | 1                | Backplane    | 160mm       | Textile         |

Table 2/3

| Catalog Number | Shock and Vibration Tolerance | Handle Included | Mounting | Complies With   | Finish               | Material |
|----------------|-------------------------------|-----------------|----------|-----------------|----------------------|----------|
| 24563-900      | 5g (force)                    | Yes             | Rack     | IEC 60297-3-103 | Anodized, Passivated | Aluminum |

| CatalogNumber | Shock and<br>Vibration<br>Tolerance | HandleIncluded | Mounting | Complies With   | Finish                  | Material |
|---------------|-------------------------------------|----------------|----------|-----------------|-------------------------|----------|
| 24563-901     | 5g (force)                          | Yes            | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-903     | 5g (force)                          | Yes            | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-910     | 5g (force)                          | Yes            | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-911     | 5g (force)                          | Yes            | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-913     | 5g (force)                          | Yes            | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-950     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-951     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-953     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-960     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-961     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |
| 24563-963     | 5g (force)                          | No             | Rack     | IEC 60297-3-103 | Anodized,<br>Passivated | Aluminum |

Table 3/3

| Catalog Number | Rack Width | Quick Ship |
|----------------|------------|------------|
| 24563-900      | 84HP       | No         |
| 24563-901      | 84HP       | No         |
| 24563-903      | 84HP       | No         |
| 24563-910      | 84HP       | No         |
| 24563-911      | 84HP       | No         |

| Catalog Number | Rack Width | Quick Ship |
|----------------|------------|------------|
| 24563-913      | 84HP       | No         |
| 24563-950      | 84HP       | No         |
| 24563-951      | 84HP       | No         |
| 24563-953      | 84HP       | No         |
| 24563-960      | 84HP       | No         |
| 24563-961      | 84HP       | No         |
| 24563-963      | 84HP       | No         |

## ADDITIONAL PRODUCT DETAILS

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**