

# Hammer-On Flange Clip, Bottom Mount



## CERTIFICATIONS



## FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

## SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)
EM24R5	191026	Spring Steel	nVent CADDY Armour	3 - 8 mm	6	450N
EM24S1	179720	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	6	200N
EM24	170050	Spring Steel	nVent CADDY Armour	3 - 8 mm	6	450N
EM24SP25	172170	Spring Steel	nVent CADDY Armour	3 - 8 mm	6	450N


CatalogNumber	Article Number	Material	Finish	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)
EM58R5	191027	Spring Steel	nVent CADDY Armour	8 - 14 mm	6	450N
EM58S1	179730	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	6	200N
EM58	170060	Spring Steel	nVent CADDY Armour	8 - 14 mm	6	450N
EM58SP25	172180	Spring Steel	nVent CADDY Armour	8 - 14 mm	6	450N
EM912SP25	175760	Spring Steel	nVent CADDY Armour	14 - 20 mm	6	450N
EM912R5	191028	Spring Steel	nVent CADDY Armour	14 - 20 mm	6	450N
EM912S1	179740	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	6	200N
EM912	170070	Spring Steel	nVent CADDY Armour	14 - 20 mm	6	450N
EM1318	170075	Spring Steel	nVent CADDY Armour	21 - 28 mm	6	450N

Table 2/2

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM24R5	191026	110N	330N	CE, 4H, EM, EBC
EM24S1	179720	110N	200N	
EM24	170050	110N	330N	ITB, CE, 4H, EM, EBC
EM24SP25	172170	110N	330N	CE, 4H, EM, EBC
EM58R5	191027	110N	330N	CE, 4H, EM, EBC
EM58S1	179730	110N	200N	
EM58	170060	110N	330N	CE, 4H, EM, EBC, ITB

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM58SP25	172180	110N	330N	CE, 4H, EM, EBC
EM912SP25	175760	110N	330N	CE, 4H, EM, EBC
EM912R5	191028	110N	330N	CE, 4H, EM, EBC
EM912S1	179740	110N	200N	
EM912	170070	110N	330N	ITB, CE, 4H, EM, EBC
EM1318	170075	110N	330N	cUL, UL

## DIAGRAMS

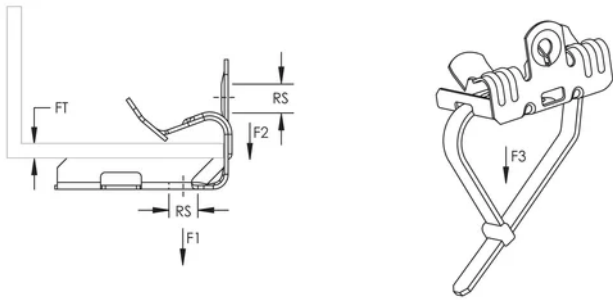

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

