


# Cast Two Bolt Beam Bonding Clamp

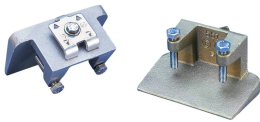

## CERTIFICATIONS



## FEATURES

Clamp for bonding cable to flat metal objects such as I-beams, angle irons and channel irons

Listed to UL® 96

## SPECIFICATIONS

**Conductor Size, UL:** Class 1 - Class 2 (4/0 Max)


Table 1/2

Catalog Number	Material	Finish	Flange Thickness (FT)	Depth (D)	Height (H)	Width (W)
LPA557	Aluminum		25.4 mm Max	69.85mm	50.8 mm	101.6 mm
LPC557	Copper		25.4 mm Max	69.85mm	50.8 mm	101.6 mm
LPC557L	Copper	Tinned	25.4 mm Max	69.85mm	50.8 mm	101.6 mm

Table 2/2

Catalog Number	Contact Area	Unit Weight
LPA557	51.61 mm <sup>2</sup> Min	0.32 kg
LPC557	51.61 mm <sup>2</sup> Min	0.93 kg
LPC557L	51.61 mm <sup>2</sup> Min	0.93 kg

## DIAGRAMS

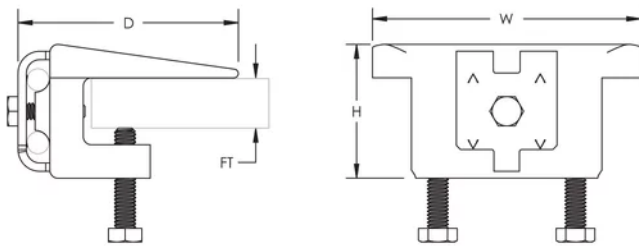

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE