

# Inspection Housing, High Density Polyethylene (HDPE)



## FEATURES

Pedestrian load rating

Suitable for lighter load rating applications in turf

Chemical, UV and corrosion resistant

3/8" x 2 1/2" (64 mm) stainless steel lock bolt included

Boxes and covers nest in 3 1/4" (83 mm) increments

Two 3 1/2" x 1 1/2" (89 x 38 mm) knockouts per box

T416BH includes four additional holes in the cover to allow water to enter the inspection well, typically for use with chemical ground rods

## SPECIFICATIONS


Table 1/2

Catalog Number	Material	Color	Load Rating	Diameter, Grade Level (DG)	Outer Diameter (OD)	Height (H)
T416B	High Density Polyethylene (HDPE)	Green	0.15	260mm	333 mm	254 mm

Table 2/2

Catalog Number	Unit Weight
T416B	2 kg

DIAGRAMS

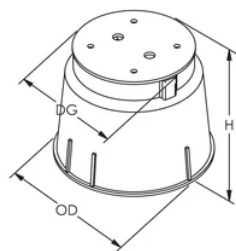

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE