

nVent ERICO Hammerlock Ground Clamp



The nVent ERICO Hammerlock irreversible mechanical connection connects the grounding conductor to the ground rod. Machined from highly conductive copper, the state-of-the-art Hammerlock provides a low resistance connection designed to withstand ground fault currents and lightning transients. The connector's mechanically rugged design will help ensure that the highest level of performance is maintained for many years after the connection has been buried in the harsh underground environment.

Installing the Hammerlock is as easy as swinging a hammer and requires no special tools or training. The Hammerlock can be installed three to five times faster than an acorn clamp and provides a high-quality grounding connection that is easy to use and withstands 100% of the current carrying capacity of the conductor.

CERTIFICATIONS



FEATURES

Irreversible connection with excellent mechanical strength

Fast and simple installation requires only a hammer

No special training required

Low resistance connection

Provides a visual indication of completed connection

Allows for "T" or pass-through connections

Suitable for Copperweld® steel conductors


SPECIFICATIONS

Material:	Copper
Ground Rod Type:	Copper-bonded

Table 1/1

Catalog Number	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size	Number of Conductors	Certifications
EHL12FC1K1K	1/2"	12.7 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	2	
EHL12FC2G	1/2"	12.7 mm	1/0 Stranded - 2/0 Stranded	1	cUL, UL
EHL12FC1V	1/2"	12.7 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	UL, cUL
EHL12FC1K	1/2"	12.7 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	1	cUL, UL
EHL58C1K1K	5/8"	14.2 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	2	cUL, UL
EHL58C1K	5/8"	14.2 mm	#6 Solid - #4 Solid, 16 mm ² Stranded, #2 Solid	1	UL, RUS, cUL
EHL58C1V	5/8"	14.2 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	UL, cUL
EHL58C2G	5/8"	14.2 mm	1/0 Stranded - 2/0 Stranded	1	UL, cUL
EHL58C2Q	5/8"	14.2 mm	3/0 Stranded - 4/0 Stranded, #2 Solid	1	cUL, UL
EHL58C1V1V	5/8"	14.2 mm	#2 Solid - #2 Stranded, #2 Solid	2	cUL, UL
EHL34C1V	3/4"	17.3 mm	#4 Stranded - #2 Stranded, 25 mm ² Stranded	1	cUL, UL
EHL34C2G	3/4"	17.3 mm	1/0 Stranded - 2/0 Stranded, #2 Solid	1	UL, cUL
EHL34C2Q	3/4"	17.3 mm	3/0 Stranded - 4/0 Stranded, #2 Solid	1	cUL, UL
EHL34C1K	3/4"	17.3 mm	#6 Solid - #4 Solid, 16 mm ² Stranded	1	UL, cUL

DIAGRAMS

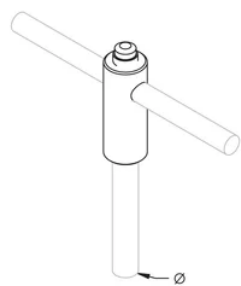

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE