


# Stamped Bolted Parallel Cable Connector

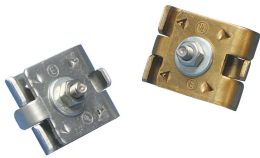

## CERTIFICATIONS



## FEATURES

For positive bolt tension cable clamping

Listed to UL® 96

## SPECIFICATIONS

**Conductor Size, UL:** Class 1 - Class 2 (4/0 Max)

Table 1/1


Catalog Number	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA502	Aluminum		38.1mm	38.1 mm	45.2 mm	0.04 kg
LPC502	Copper		38.1mm	38.1 mm	45.2 mm	0.09 kg
LPC502A	Copper, Aluminum, Stainless Steel 304 (EN 1.4301)		38.1mm	38.1 mm	45.2 mm	0.09 kg

CatalogNumber	Material	Finish	Depth (D)	Height (H)	Width (W)	Unit Weight
LPC502L	Copper	Tinned	38.1mm	38.1 mm	45.2 mm	0.09 kg

## ADDITIONAL PRODUCT DETAILS

Stainless steel separator included with LPC502A for bi-metallic applications.

## DIAGRAMS

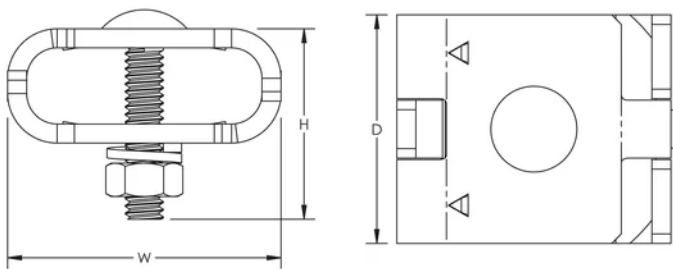

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**