

BC Ribbed Steel Busbar Clamp



CERTIFICATIONS



FEATURES

Connects two copper busbars together or nVent ERIFLEX Flexibar to copper busbar

Two ribbed plates complete with screws

Allows for excellent electrical contact

Installs quickly and easily

Ideal for on site modifications

RoHS compliant

SPECIFICATIONS

Clamping Capacity: 20mm
Finish: Electrogalvanized
Material: Steel


Table 1/2

| Catalog Number | Article Number | Busbar Width | Width (W) | A | Screw Diameter (Sc) | Torque (TQ) |
|----------------|----------------|--------------|-----------|-------|---------------------|-------------|
| BC80 | 553250 | 80 mm | 118 mm | 96 mm | 10 | 29.5 N·m |

| CatalogNumber | Article Number | Busbar Width | Width (W) | A | ScrewDiameter (Sc) | Torque (TQ) |
|---------------|----------------|--------------|-----------|--------|--------------------|-------------|
| BC30 | 553200 | 30 mm | 56 mm | 42 mm | 6 | 7 N·m |
| BC40 | 553210 | 40 mm | 66 mm | 52 mm | 6 | 7 N·m |
| BC50 | 553220 | 50 mm | 83 mm | 64 mm | 8 | 20 N·m |
| BC63 | 553230 | 63 mm | 93 mm | 74 mm | 8 | 20 N·m |
| BC100 | 553260 | 100 mm | 144 mm | 118 mm | 10 | 29.5 N·m |

| Table 2/2 | | |
|----------------|----------------|-------------|
| Catalog Number | Article Number | Unit Weight |
| BC80 | 553250 | 0.12 kg |
| BC30 | 553200 | 0.31 kg |
| BC40 | 553210 | 0.37 kg |
| BC50 | 553220 | 0.59 kg |
| BC63 | 553230 | 0.74 kg |
| BC100 | 553260 | 1.72 kg |

DIAGRAMS

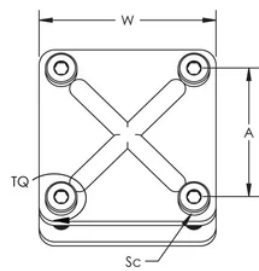

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE