

P9 Position Coupler, Plain



CERTIFICATIONS



FEATURES

Designed to splice the same diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

SPECIFICATIONS

Finish: Plain

Material: Steel

Table 1/3

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)
EL20P9N	20 mm	#6	20M	46 mm	109 mm	124 mm
EL25P9N	25 mm	#8	25M	46 mm	125 mm	140 mm
EL22P9N	22 mm	#7		46 mm	117 mm	132 mm

CatalogNumber	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 1 (L1)	Length 2 (L2)
EL28P9N	28 mm	#9	30M	64 mm	128 mm	144 mm
EL32P9N	32 mm	#10		64 mm	135 mm	151 mm
EL36P9N	36 mm	#11	35M	64 mm	145 mm	160 mm
EL38P9N	38 mm	#12		76 mm	150 mm	164 mm
EL57TP9N	57 mm	#18	55M	102 mm	267 mm	288 mm
EL40P9N	40 mm			76 mm	161 mm	175 mm
EL43TP9N	43 mm	#14	45M	76 mm	224 mm	245 mm

Table 2/3						
Catalog Number	Bar Depth (BD)	Bar Gap 1 (BG1)	Bar Gap 2 (BG2)	Coupler Body (CB)	Unit Weight	Package Quantity
EL20P9N	28mm	53mm	68mm	70mm	1.16 kg	12
EL25P9N	34mm	57mm	72mm	86mm	1.19 kg	12
EL22P9N	32mm	53mm	68mm	78mm	1.19 kg	12
EL28P9N	38mm	52mm	68mm	90mm	2.61 kg	6
EL32P9N	40mm	55mm	71mm	97mm	2.63 kg	6
EL36P9N	43mm	59mm	74mm	106mm	4.3 kg	6
EL38P9N	44mm	62mm	76mm	94mm	4.35 kg	4
EL57TP9N	71mm	125mm	146mm	156mm	11.09 kg	2
EL40P9N	55mm	51mm	65mm	105mm	5.3 kg	4

CatalogNumber	Bar Depth (BD)	Bar Gap 1(BG1)	Bar Gap 2(BG2)	Coupler Body (CB)	Unit Weight	Package Quantity
EL43TP9N	56mm	112mm	133mm	127mm	8.88 kg	4

Table 3/3


Catalog Number	Certifications
EL20P9N	DCL
EL25P9N	DCL
EL22P9N	
EL28P9N	
EL32P9N	DCL
EL36P9N	
EL38P9N	
EL57TP9N	
EL40P9N	
EL43TP9N	

Designed to Meet: AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600

ADDITIONAL PRODUCT DETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

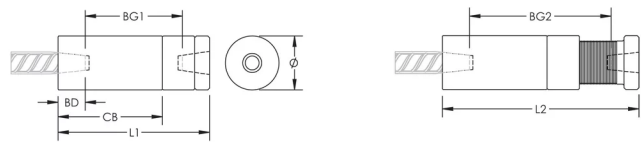

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE