
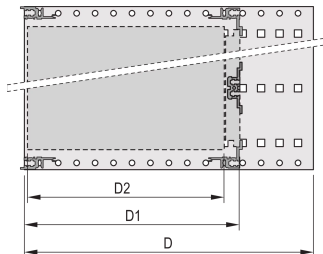
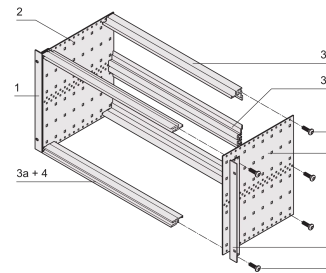


# EuropacPRO 19" Subrack Kit for DIN Connector, Slide Rail, 6 U, 235 mm

## Power Utilities

### CATALOG NUMBER

**24553-492**

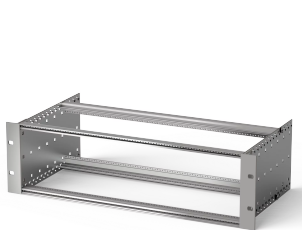

Non-shielded subrack for Din Connector mounting EN 60603-2 , Subrack can be assembled on slide rails to support the subrack inside a cabinet.

### CERTIFICATIONS



### FEATURES

Subrack with side panel type F ("flexible"), 19" bracket with notch for slide rail assembly

Installed load up to 11 kg

Subrack can be used with slide rails

Horizontal rails, rear, for connector mounting (IEC 60603-2 / DIN 41612)

Threaded insert pre-fitted

## PRODUCT ATTRIBUTES

---

Product Type: Subrack/Chassis

Rack Height: 6 U

Rack Width: 84 HP

Depth: 235 mm

For Mounting: DIN Connector

Board Depth: 160 mm; 220 mm

EMC Shielding: No

Gasket Type: Stainless Steel

Static Load: 11 kgf

Handle Included: No

Mounting: Rack

Complies With: IEC 60297-3-103

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**