


# Aisle Containment Top Cover

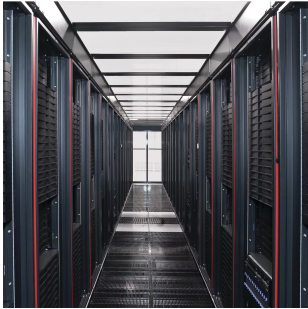

Top cover in different depths to setup a aisle containment closing.

## CERTIFICATIONS



## FEATURES

Top covers to provide top cover for 2 cabinet rows

Suitable for an aisle width of 1200 mm

A top cover profile can raise the aisle height by 84 mm; please order separately

Top cover can be removed from inside (allows access to lighting and facilitates maintenance works)

## SPECIFICATIONS

**Works With:** Aisle Containment

**Product Type:** Cover

Table 1/2

| Catalog Number | Type            | Width | Depth  | Material | Package Quantity | Color      |
|----------------|-----------------|-------|--------|----------|------------------|------------|
| 21130-649      | Aisle Top Cover | 200mm | 1200mm | Steel    | 1                | Black Grey |
| 21130-648      | Aisle Top Cover | 300mm | 1200mm | Steel    | 1                | Black Grey |

| CatalogNumber | Type            | Width | Depth  | Material     | Package Quantity | Color      |
|---------------|-----------------|-------|--------|--------------|------------------|------------|
| 21130-589     | Aisle Top Cover | 800mm | 1200mm | Steel, Glass | 1                | Black Grey |
| 21130-588     | Aisle Top Cover | 600mm | 1200mm | Steel, Glass | 1                | Black Grey |

| Table 2/2      |            |               |                |            |
|----------------|------------|---------------|----------------|------------|
| Catalog Number | Color Code | Finish        | Certifications | Quick Ship |
| 21130-649      | RAL 7021   | Powder Coated |                | No         |
| 21130-648      | RAL 7021   | Powder Coated | RoHS           | No         |
| 21130-589      | RAL 7021   | Powder Coated | RoHS           | No         |
| 21130-588      | RAL 7021   | Powder Coated | RoHS           | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**