


EuropacPRO 19" Subrack Kit for Railway, Shielded, EN 50155, CompactPCI, 6 U, 84 HP, 235 mm

CATALOG NUMBER

21500-082

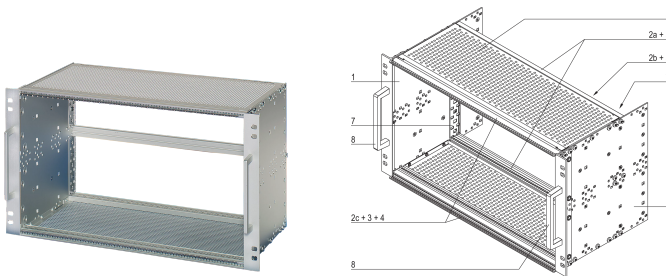

Subrack for Railway applications, conform to EN50155 standard, for Compact PCI applications.

CERTIFICATIONS



FEATURES

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Supplied as space-saving flat-pack

PRODUCT ATTRIBUTES

Rack Height: 6U
Package Quantity: 1
For Mounting: Backplane
Board Depth: 160mm
Gasket Type: Textile EMC
Shock and Vibration Tolerance: 5g (force)
Handle Included: Yes
Mounting: Rack
Complies With: IEC 60297-3-103; IEEE 1101.10; IEEE 1101.11; EN 50155 part 12.2.11
Depth: 235mm
EMC Shielding: Yes
Finish: Anodized; Passivated
Material: Aluminum
Product Type: Subrack/Chassis
Rack Width: 84HP
Static Load: 15kg
Net Weight: 2.64kg

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE