


EuropacPRO Front Panel for 19" Module Support, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

CATALOG NUMBER

24563-096

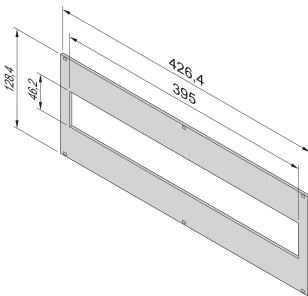

Front panel with cut-out in accordance with DIN 43880 (for power distribution modules).

CERTIFICATIONS



FEATURES

Front panel with cut-out conforming to DIN 43880 (for power distribution modules)

Height 3 U, width 84 HP

PRODUCT ATTRIBUTES

Product Type: Front Panel

Product Family: EuropacPRO

Accessory Type: Front panel

Mounting: Screw-on Front

Material: Aluminum

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3U

Height: 128.4mm

Rack Width: 84HP

Width: 426.4mm

Depth: 2.5mm

Package Quantity: 1

Finish: Anodized; Passivated

Net Weight: 0.38kg

ADDITIONAL PRODUCT DETAILS

2 Plastic cover strips are included in the form of delivery.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE