


# RatiopacPRO 19" Tower Case, Retrofittable Shielding, Front Trim, 4 U, 84 HP, 495 mm

## CATALOG NUMBER

**24571-395**

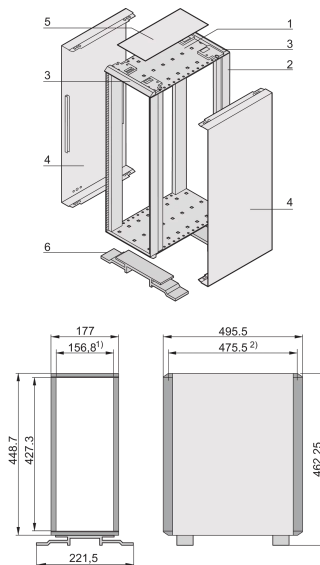

The nVent SCHROFF RatiopacPRO tower case provides electronics protection for 19" assemblies. This flexible and robust case is simple to convert from desktop to a 19" rack mount case and includes four different style options. This version of the case provides a sleek design and feet for desktop applications.

## CERTIFICATIONS



## FEATURES

Case based on RatiopacPRO with case feet

Mounting space 4 U, 84 HP, depth 475 mm

Retrofittable EMC shielding

Symmetrical design, identical front and rear side

Conforms with DIN EN 62368-1

PRODUCT ATTRIBUTES

Product Type: Case
Product Family: RatiopacPRO
Type: Tower
Rack Height: 4U
Height: 177mm
Usable Height: 156.8mm
Rack Width: 84HP
Width: 448.9mm
Usable Width: 432mm
Depth: 495.5mm
EMC Shielding: No (Retrofittable)
Static Load: 25kg
Protection Rating: IP20
Front Frame Construction: Side Trim; Horizontal Rails
Cooling Option: No
Complies With: IEC 60297-3-101; IEC 60297-3-102; IEEE 1101.1; IEEE 1101.10; IEEE 1101.11
Package Quantity: 1
Finish: Passivated; Powder Coated
Material: Aluminum

ADDITIONAL PRODUCT DETAILS

- Modifications (special colours or sizes).
- Custom solutions (cut-outs in top cover, base plate or side panels).
- Assembly service from 1 piece.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**