


# EuropacPRO Mounting Plate for Use With Cover Plate

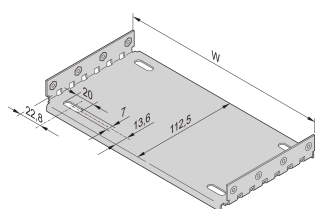

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## CERTIFICATIONS



## FEATURES

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

## SPECIFICATIONS

<b>Material:</b>	Aluminum
<b>Product Family:</b>	EuropacPRO
<b>Product Type:</b>	Mounting Plate
<b>Works With:</b>	Subracks

Table 1/1

Catalog Number	Rack Width	Package Quantity	Depth	Width	Certifications	Quick Ship
----------------	------------	------------------	-------	-------	----------------	------------

34563-004	84HP	1	112.5mm	431.35mm	RoHS	No
34563-024	84HP	1	172.5mm	431.35mm	RoHS	No
34563-026	84HP	1	232.5mm	431.35mm		No
34563-028	84HP	1	292.5mm	431.35mm		No
34563-042	84HP	1	352.5mm	431.35mm		No
34563-044	84HP	1	412.5mm	431.35mm		No
34563-001	28HP	1	112.5mm	146.88mm	RoHS	No
34563-002	42HP	1	112.5mm	217.99mm	RoHS	No
34563-003	63HP	1	112.5mm	324.67mm	RoHS	No
34563-009	28HP	1	172.5mm	146.88mm	RoHS	No
34563-014	42HP	1	172.5mm	217.99mm	RoHS	No
34563-019	63HP	1	172.5mm	324.67mm	RoHS	No

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**