


# Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

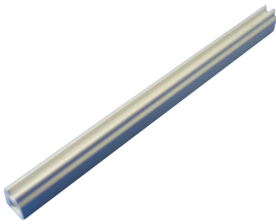

## FEATURES

Middle profile for mounting guide rails for 2.5 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

## SPECIFICATIONS

Table 1/2

Catalog Number	Board Depth	Color	Finish	Groove Width	Material	Package Quantity
34562-813	160mm	Silver	Anodized	2.5	Aluminum	1
34562-814	220mm	Silver	Anodized	2.5	Aluminum	1
34562-815	280mm	Silver	Anodized	2.5	Aluminum	1
34562-816	340mm	Silver	Anodized	2.5	Aluminum	1
34562-822	1000mm	Silver	Anodized	2.5	Aluminum	1

Table 2/2

Catalog Number	Type	Works With	Quick Ship
34562-813	Middle Section	Subracks, Cases, Chassis	No
34562-814	Middle Section	Subracks, Cases, Chassis	No
34562-815	Middle Section	Subracks, Cases, Chassis	No
34562-816	Middle Section	Subracks, Cases, Chassis	No
34562-822	Middle Section	Subracks, Cases, Chassis	No

## ADDITIONAL PRODUCT DETAILS

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**