


# MultipacPRO 19" Chassis Basic Kit

Such a kit enables a customer to configure the 3 different top / bottom covers.

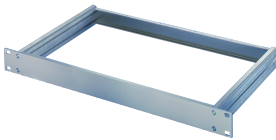

## CERTIFICATIONS



## FEATURES

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

## SPECIFICATIONS

|                        |                    |
|------------------------|--------------------|
| <b>Material:</b>       | Aluminum           |
| <b>Type:</b>           | Configurable       |
| <b>Product Family:</b> | MultipacPRO        |
| <b>EMC Shielding:</b>  | No (Retrofittable) |
| <b>Product Type:</b>   | Subrack/Chassis    |

Table 1/2

| Catalog Number | Rack Height | Depth | Usable Width | Mounting | Complies With   | Certifications |
|----------------|-------------|-------|--------------|----------|-----------------|----------------|
| 20860-201      | 1U          | 220mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |

| CatalogNumber | Rack Height | Depth | Usable Width | Mounting | Complies With   | Certifications |
|---------------|-------------|-------|--------------|----------|-----------------|----------------|
| 20860-202     | 1U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-203     | 1U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-204     | 1U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 |                |
| 20860-205     | 1U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 |                |
| 20860-210     | 2U          | 220mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-231     | 4U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-211     | 2U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-212     | 2U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-213     | 2U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 |                |
| 20860-214     | 2U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 |                |
| 20860-219     | 3U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-220     | 3U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-221     | 3U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-228     | 4U          | 280mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-222     | 3U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-229     | 4U          | 340mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-230     | 4U          | 400mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |
| 20860-240     | 5U          | 460mm | 403mm        | Rack     | IEC 60297-3-100 | RoHS           |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 20860-201      | No         |
| 20860-202      | No         |
| 20860-203      | No         |
| 20860-204      | No         |
| 20860-205      | No         |
| 20860-210      | No         |
| 20860-231      | No         |
| 20860-211      | No         |
| 20860-212      | No         |
| 20860-213      | No         |
| 20860-214      | No         |
| 20860-219      | No         |
| 20860-220      | No         |
| 20860-221      | No         |
| 20860-228      | No         |
| 20860-222      | No         |
| 20860-229      | No         |
| 20860-230      | No         |

| Catalog Number | Quick Ship |
|----------------|------------|
| 20860-240      | No         |

## ADDITIONAL PRODUCT DETAILS

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**