


Varistar 19" Swing Frame Trim

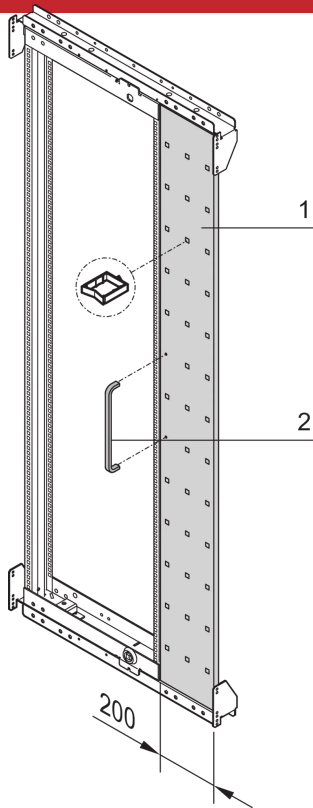

Varistar swing frame provides optimum space usage inside the rack. The swing frames come with handles.

CERTIFICATIONS



FEATURES

Includes handle and cut-out for cable eyes

To cover the gap between swing frame and cabinet upright for 800 mm wide cabinets

Max. swing bracket: 120 or 160

For swing frame with load-carrying capacity 150 kg, a stop is recommended for security reasons

Locking no. 333

Spare key for DIN semi-profile cylinder

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Material	Frame Material	Color	Color Code	Rack Height
21130-432	Swing	Steel	Steel	Black Grey	RAL 7021	25U
21130-433	Swing	Steel	Steel	Black Grey	RAL 7021	29U
21130-434	Swing	Steel	Steel	Black Grey	RAL 7021	33U
21130-435	Swing	Steel	Steel	Black Grey	RAL 7021	38U
21130-436	Swing	Steel	Steel	Black Grey	RAL 7021	42U
21130-437	Swing	Steel	Steel	Black Grey	RAL 7021	47U
21130-442	Swing	Steel	Steel	Black Grey	RAL 7021	25U
21130-443	Swing	Steel	Steel	Black Grey	RAL 7021	29U
21130-444	Swing	Steel	Steel	Black Grey	RAL 7021	33U
21130-445	Swing	Steel	Steel	Black Grey	RAL 7021	38U
21130-446	Swing	Steel	Steel	Black Grey	RAL 7021	42U
21130-447	Swing	Steel	Steel	Black Grey	RAL 7021	47U

Table 2/2

Catalog Number	Width	Works With	Finish	Package Quantity	Quick Ship
21130-432	800mm	Varistar	Powder Coated	1	No
21130-433	800mm	Varistar CP	Powder Coated	1	No
21130-434	800mm	Varistar	Powder Coated	1	No
21130-435	800mm	Varistar CP	Powder Coated	1	No

Catalog Number	Width	Works With	Finish	Package Quantity	Quick Ship
21130-436	800mm	Varistar	Powder Coated	1	No
21130-437	800mm	Varistar CP	Powder Coated	1	No
21130-442	800mm	Varistar	Powder Coated	2	No
21130-443	800mm	Varistar CP	Powder Coated	2	No
21130-444	800mm	Varistar	Powder Coated	2	No
21130-445	800mm	Varistar CP	Powder Coated	2	No
21130-446	800mm	Varistar	Powder Coated	2	No
21130-447	800mm	Varistar CP	Powder Coated	2	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE