


# Varistar CP Flat Top Cover With Pre-Cutout Zones

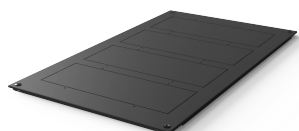

Rack top cover with micro perforated cut out zones.  
Brushes, edge protection or cover panle have to chosen  
form the accessory range.

## FEATURES

Flat top cover with pre-cutout zones

## SPECIFICATIONS

**Product Type:** Cabinet/Rack Top Cover  
**Color Code:** RAL 7021  
**Material:** Steel

Table 1/1

| Catalog Number | Width | Depth  | Package Quantity | Color      | Type       | Quick Ship |
|----------------|-------|--------|------------------|------------|------------|------------|
| 21630-457      | 600mm | 600mm  | 1                | Black Grey | Cutout     | No         |
| 21630-458      | 600mm | 800mm  | 1                | Black Grey | Cutout     | No         |
| 21630-459      | 600mm | 900mm  | 1                | Black Grey | Cutout     | No         |
| 21630-005      | 600mm | 1000mm | 1                | Black Grey | Perforated | No         |
| 21630-460      | 800mm | 600mm  | 1                | Black Grey | Cutout     | No         |

| CatalogNumber | Width | Depth  | Package Quantity | Color      | Type       | Quick Ship |
|---------------|-------|--------|------------------|------------|------------|------------|
| 21630-461     | 800mm | 800mm  | 1                | Black Grey | Cutout     | No         |
| 21630-462     | 800mm | 900mm  | 1                | Black Grey | Cutout     | No         |
| 21630-024     | 800mm | 1000mm | 1                | Black Grey | Perforated | No         |
| 21630-012     | 600mm | 1100mm | 1                | Black Grey | Perforated | No         |
| 21630-023     | 600mm | 1200mm | 1                | Black Grey | Perforated | No         |
| 21630-026     | 800mm | 1200mm | 1                | Black Grey | Perforated | No         |
| 21630-025     | 800mm | 1100mm |                  | Black Grey | Perforated | No         |

## ADDITIONAL PRODUCT DETAILS

Please order brushes, cover panels from the accessory range.

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**