


# Stamped Bonding Plate

## Power Utilities

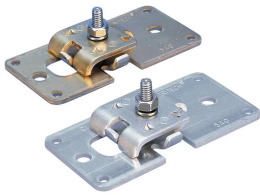

### FEATURES

Stamped bonding plate suitable for structural steel applications

Listed to UL® 96

### SPECIFICATIONS

Table 1/2

| Catalog Number | Conductor Size, UL          | Contact Area               | Height (H) | Width (W)  | Hole Size 1 (HS1) | Hole Size 2 (HS2) |
|----------------|-----------------------------|----------------------------|------------|------------|-------------------|-------------------|
| LPA540         | Class 1 - Class 2 (4/0 Max) | 51.600 cm <sup>2</sup> Min | 31.75 mm   | 107.950 mm | 5.1 mm            | 7.9 mm            |


Table 2/2

| Catalog Number | Unit Weight |
|----------------|-------------|
| LPA540         | 0.088 kg    |

### ADDITIONAL PRODUCT DETAILS

Stainless steel separator included with LPC540A for bi-metallic applications.

DIAGRAMS

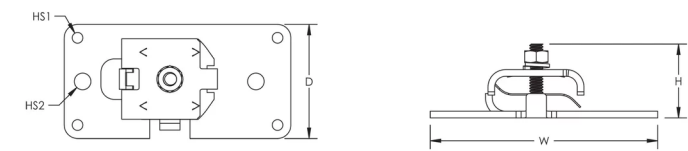

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

|       |       |         |       |         |         |
|-------|-------|---------|-------|---------|---------|
| CADDY | ERICO | HOFFMAN | ILSCO | SCHROFF | TRACHTE |
|-------|-------|---------|-------|---------|---------|