


# Varistar Mounting Plate

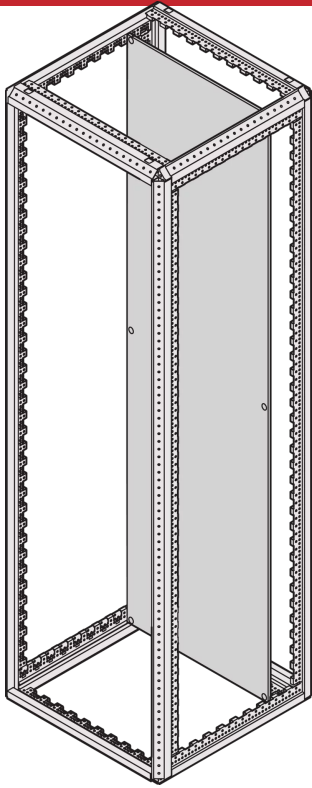

Varistar Mounting Plate for mounting electrical components and sub-assemblies, with 600 kg load capacity. The mounting plate can also be rear mounted and strengthening bracket can be added to increase load capacity.

## CERTIFICATIONS

---



## FEATURES

---

For mounting electrical components and sub-assemblies including cabling

Mounting pitch 25 mm in depth and 50 mm in height for partial-height mounting

Static load-carrying capacity up to 450 kg (rear mounted)

600 kg at full height, mounted to rear, with additional strengthening brackets

Strengthening bracket increases static load-carrying capacity

SPECIFICATIONS

Product Type: Mounting Plate  
Material: Steel

| Table 1/1      |        |       |                  |             |            |
|----------------|--------|-------|------------------|-------------|------------|
| Catalog Number | Height | Width | Package Quantity | Finish      | Quick Ship |
| 23130-405      | 1800mm | 600mm | 1                | Zinc Plated | No         |
| 23130-414      | 1200mm | 800mm | 1                | Zinc Plated | No         |
| 23130-407      | 2000mm | 600mm | 1                | Zinc Plated | No         |
| 23130-408      | 2000mm | 800mm | 1                | Zinc Plated | No         |
| 23130-413      | 1200mm | 600mm | 1                | Zinc Plated | No         |
| 23130-406      | 1800mm | 800mm | 1                | Zinc Plated | No         |

ADDITIONAL PRODUCT DETAILS

Depth members are required for partial-height mounting.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**